


Features

- The Inserts are available in the most popular sizes 24 PE, 42 PE, 72 PE and 108 PE. UL approved.

RS PRO Industrial Power Connectors

RS Stock No.: 0457208, 0457206,
0457203

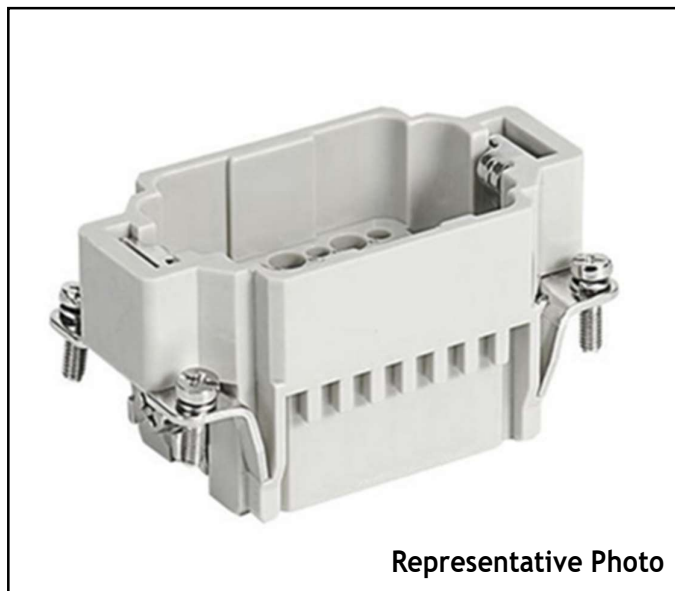

Representative Photo

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

General Specifications

Flammability acc. to UL 94	V 0
Limiting temperature	-40 ... +125 °C
Mating cycles	□500
Material (insert)	Polycarbonate
Material (Contacts)	Copper alloy (Hard-Silver Plated)

Mechanical Specifications

Termination	Crimp terminal
Cable Entry	Back
Electrical Data	
acc. to EN 61984	10 A 250 V 4 kV 3
Wire gauge	0.14 2.5 mm ²
Stripping Length	8 mm (2.5mm ² 6mm)
Tightening Torque	0.5 Nm
Mechanical Working Life	□500
AWG	26-14
Identification of contacts	24-42-72-108

Electrical Specifications

Insulation resistance	□10 ¹⁰ Ω
Contact Resistance	□3 mΩ

Male insert (M) Part Number: 0457208	(1) distance for contact max. 21mm Panel cut out
---	--

RS Pro 108 DD 10 A 250 V 4 kV 3		Size 24 B	
Male insert (M) Part Number: 0457206	Female insert (F) Part Number: 0457203	(1) distance for contact max. 21mm Panel cut out	