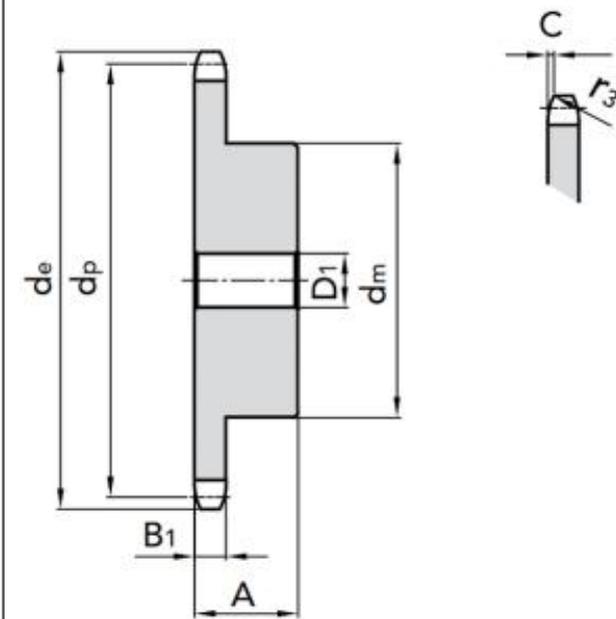


**10115015**

pitch 5/8in x 3/8in - Chain sprockets ASA

**2D Technical Drawing**

**Dynamic 3D View**

**Technical Specifications**

Number of teeth (T)	15
de (DE) mm	83.00
dp (DP) mm	76.36
Part number (CODE)	10115015
dm (DM) mm	57
D1 (D1) mm	12
A (A) mm	30
Tooth radius r3 (R3) mm	17
Radius width C (C) mm	2
Sprockets tooth width B1 (B1) mm	9
Weight (WEIGHT) kg	0.67
Material (MAT)	STEEL C45