


Separate units ø 22: Heads

IP 66
To be combined with a clip and electrical blocks (p. 48)
Equipped with a locking ring
Plastic black bezel
Conform to IEC 60947-5-1

 Characteristics (p. 94)
Cross reference list (p. 311)

► MUSHROOM HEAD - NON ILLUMINATED (CONTINUED)


Ø 40 - STAY-PUT

Push-pull to reset

Cat. No.



L22DD01

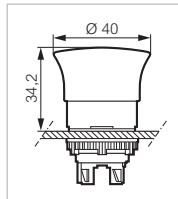

- Red
- Black


L22DD01
L22DD03

Ø 40 - STAY-PUT

Key to reset



L22GM01

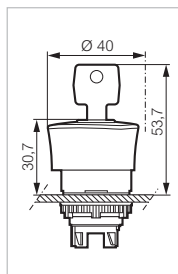

Supplied with 2 keys profile n° 455

- Red

L22GM01

► EN 418/ISO 13850 EMERGENCY STOP - NON ILLUMINATED


Ø 32 EN 418/ISO 13850 - STAY-PUT

Push-pull

Cat. No.



L22DQ01

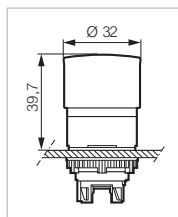

Head position visible from the side with yellow collar
Compliant with the requirements of emergency stop:
IEC 60947-5-5 / EN 418/ISO 13850

- Red


L22DQ01

Ø 32 EN 418/ISO 13850 - STAY-PUT

Key to reset



L22GQ01

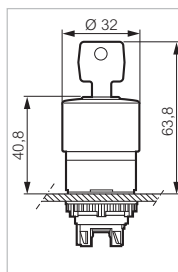

Supplied with 2 keys profile n° 455
Head position visible from the side with yellow collar
Compliant with the requirements of emergency stop:
IEC 60947-5-5 / EN 418/ISO 13850

- Red

L22GQ01

Catalogue No. in bold: normally in stock at distribution outlets