


M12 MALE 0° SHIELDED WIREABLE SCREW TERM.

5-pol. max.0,75mm² 6-8mm


[Link to Product](#)

Illustration

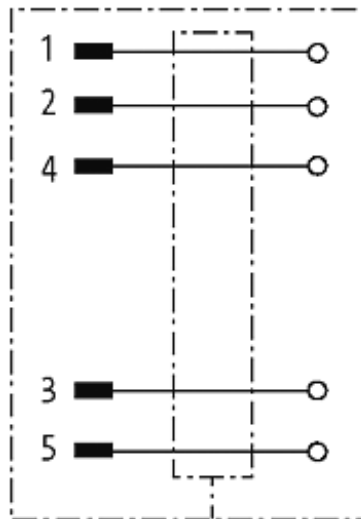

Male



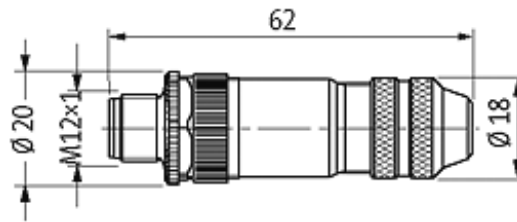

Product may differ from Image

Form

Form 13321

Technical Data

Operating voltage	max. 60 V AC/DC
Operating current per contact	max. 4 A
Connection cross section	max. 0.75 mm ²
Sealing range (cable Ø)	6...8 mm
Protection	IP67 inserted and tightened (EN 60529)
Housing	Brass, nickel plated

General data

Temperature range -25...+85 °C

Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879198837
eClass	27279218
minimum order quantity	1