




607 CT FLON

WHITE TEFLON GREASE

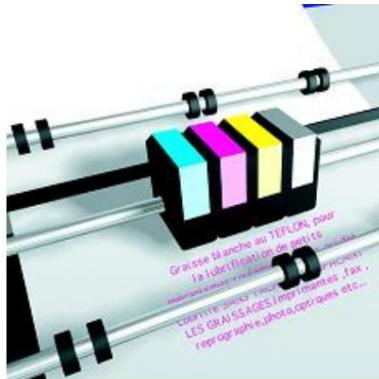

BENEFITS

- The presence of Teflon® considerably improves the coefficient of friction, both in static and dynamic lubrication. • The micronization of these particles allows the lubricant to penetrate into the smallest gaps.
- Lubricating power is ensured up to temperatures high thanks to Teflon® which allows dry lubrication in extreme cases (not exceeding 250°C)
- The elaborate composition of CT FLON allows spacing out the lubrication rates and reduce the noise of various mechanisms and good resistance to water and dust.
- Anti-wear and anti-corrosion additives.

DEFINITION

CT FLON is a clean, TEFILON® Extreme Pressure universal grease .

INSTRUCTIONS FOR USE

Clean the parts and remove as much of the old grease deposits as possible before applying CT FLON.

FEATURES

Savo:	Lithium
Color :	Ivoire
Operating temperature:	-20 to +140°C
Dropping point (NFT 60-102):	180°C
NLGI Grade:	2
Penetration worked (NFT 60-132):	265-295
4-ball soldering test:	> 315kg (ASTM D 2596)



FIELD OF APPLICATION

CT FLON is particularly suitable when you want to reduce the coefficient of friction in the following cases: Ball bearings, needles and rollers, bearings, joints, construction and public works equipment, handling and transport equipment, and all delicate mechanisms requiring the use of a lubricant improving friction.

PACKAGING

Bucket 5 kg	ref. 3607S1	x1
Box 1 kg	ref. 3607B7	x6
Cartouche 400 g	ref. 3607C4	x12
Aerosol 650 ml	ref. 4607A4	x12

ORAPI® cannot be aware of all the applications in which its products are used and the conditions of their use. ORAPI® assumes no responsibility for: the suitability of its products for a given use or for a particular purpose, the application methods over which it has no control. The information contained in this technical data sheet must in no case replace the preliminary tests that must be carried out to verify the suitability of the product for each intended application. The user of the product described in this technical data sheet remains solely responsible for all measures required to protect people and property against all risks that may result from the implementation and/or use of this product. Consequently, ORAPI® disclaims all implied or explicit warranties, including warranties relating to the fitness for sale or suitability for a particular need, resulting from the sale or use of its products. ORAPI® specifically denies any prosecution for incidental or consequential damages of any kind, including financial operating losses.