




**Part Number :** [781192010](#)

**Product Description :** Easy-On FFC/FPC Connector, 0.50mm Pitch, Surface Mount, Vertical, Non-ZIF, Standard Footprint, Tin Bismuth Plating, Short Terminal Type, Black, 20 Circuits

**Series Number :** 78119

**Status :** Active

**Product Category :** FFC / FPC Connectors

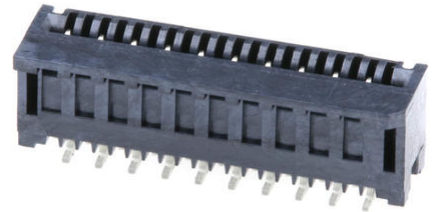

---

## Documents & Resources

### Drawings

[781192010 sd.pdf](#)

### 3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

[Symbol and Footprint \(Multi-Format\)](#)

### Specifications


[781199200-200.pdf](#)

[781190001-000.pdf](#)

---

## Product Environment Compliance

### Compliance

GADSL/IMDS	Compliant with Exemption 44; 33
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

[Compliance Statements](#)

- EU RoHS
- REACH SVHC
- Low-Halogen

#### Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

#### Substances of Interest

- PFAS

#### EU RoHS Certificate of Compliance

#### Additional Product Compliance Information

## Part Details

### General

Status	Active
Category	FFC / FPC Connectors
Series	78119
Description	Easy-On FFC/FPC Connector, 0.50mm Pitch, Surface Mount, Vertical, Non-ZIF, Standard Footprint, Tin Bismuth Plating, Short Terminal Type, Black, 20 Circuits
Product Name	Easy-On
UPC	889056670524

### Electrical

Current - Maximum per Contact	0.5A
Voltage - Maximum	50V

### Physical

Actuator Type	Non-ZIF
Circuits (Loaded)	20
Color - Resin	Black
Contact Position	N/A
Durability (mating cycles max)	10

Mated Height	4.10mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin-Bismuth
Material - Plating Termination	Tin-Bismuth
Material - Resin	Liquid Crystal Polymer
Net Weight	211.320/mg
Orientation	Vertical
Packaging Type	Embossed Tape on Reel
PCB Locator	No
PCB Mounting	Surface Mount
PCB Retention	None
Pitch - Mating Interface	0.50mm
Pitch - Termination Interface	0.50mm
Plating min - Mating	1.000µm
Polarized to PCB	No
Stackable	No
Temperature Range - Operating	-40° to +85°C
Wire/Cable Type	FFC/FPC

---

## Mates With / Use With

### Mates with Part(s)

Description	Part Number
0.50mm Pitch Premo-Flex FFC Jumpers	<u>15166</u>
0.50mm Pitch Premo-Flex FFC Jumpers	<u>15266</u>
0.50mm Pitch Premo-Flex FFC Jumpers	<u>98266</u>
0.50mm Pitch Premo-Flex FFC Jumpers	<u>15366</u>