

FICHE TECHNIQUE STC911P




Longueur (mm) : 380 (360)
Largeur (mm) : 260 (240)
Hauteur (mm) : 90 (80)
Poids (kg) : 1.50
Charge maximum (kg) : 9
Fabriqué en : aluminium / MDF / acier / PVC
Coloris : argent

Gamme : STORAGE
Code usine : C5
Code douane : 4202191000
EAN : 3321369931031

Autres :

- Malette de protection aluminium
- Extérieur en PVC
- 3 Charnières acier à l'arrière
- Coins renforcés
- Serrures à combinaisons
- Mousse prédécoupée dans le fond densité 24 kg / m3
- Mousse crantée sur le dessus
- 4 pieds pour la poser à terre

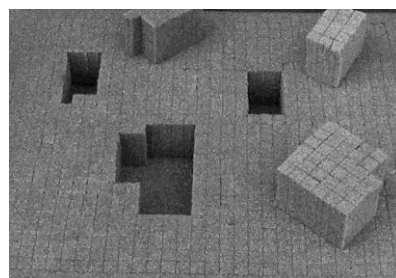

TECHNICAL SHEET

STC911P



Lenght (mm) : 380 (360)
Widht (mm) : 260 (240)
Height (mm) : 90 (80)
Weight (kg) : 1.50
Maximum load capacity (kg) : 9
Made of : aluminium / MDF / steel / PVC
Colors : silver

Range: STORAGE
Factory: C5
Custom: 4202191000
EAN : 3321369931031

Others :

- Aluminium case
- Outside wall made of PVC
- 3 steel hinges
- Reinforces corner
- Combination locks
- Precuttet foam of the bottom density 24 kg / m3
- Alveolate foam on the top
- 4 feet for laying on the floor

