


USE WITH PAD SAVERS FOR ADVANCED DUST REDUCTION AND EFFICIENCY SANDING WOOD, PAINT, AND DRYWALL

EXPERT M480 Sanding Net

EXPERT

- ① Highly efficient dust removal with Bosch Particle Control
- ② Dust is sucked through the open net structure

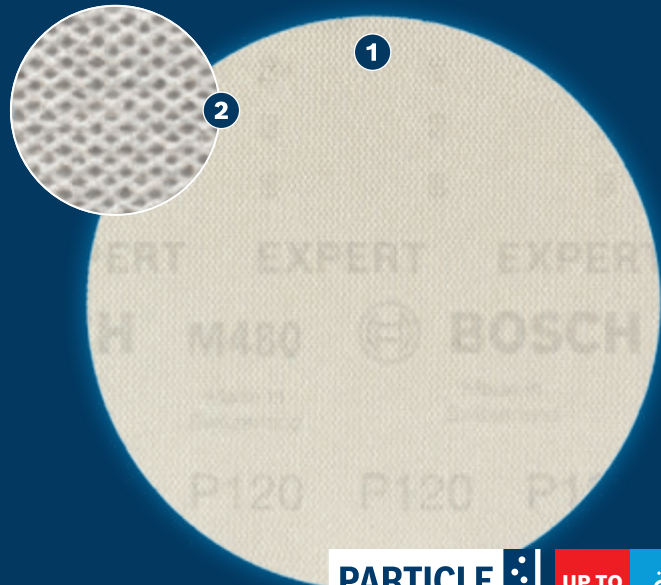

PARTICLE CONTROL

UP TO
4x*



NO DUST

* vs. Bosch C420



Video



BOSCH

EXPERT M480 SANDING NET



- ▶ Ideal for highly effective low-dust sanding of flat surfaces; to roughen and prepare surfaces for painting; and to prepare or finish drywall
- ▶ EXPERT Abrasives - the very best for all trades
- ▶ Up to 4x better dust reduction than Bosch C420 Sandpaper
- ▶ Just stick it on with hook and loop



PRODUCT PROPERTIES			ORDERING INFORMATION					Part number
Disc diameter mm	Grit	Perforation	Packaging type	Pack quantity	Minimum order quantity	Barcode 4 059 952...		
125	80	open net	C1a	5	5	540 092	2 608 900 671	
125	100	open net	C1a	5	5	540 108	2 608 900 672	
125	120	open net	C1a	5	5	540 115	2 608 900 673	
125	150	open net	C1a	5	5	540 122	2 608 900 674	
125	180	open net	C1a	5	5	540 139	2 608 900 675	
125	220	open net	C1a	5	5	540 146	2 608 900 676	
125	240	open net	C1a	5	5	540 153	2 608 900 677	
125	320	open net	C1a	5	5	540 160	2 608 900 678	
125	400	open net	C1a	5	5	540 177	2 608 900 679	
150	80	open net	C1a	5	5	540 276	2 608 900 689	
150	100	open net	C1a	5	5	540 283	2 608 900 690	
150	120	open net	C1a	5	5	540 290	2 608 900 691	
150	150	open net	C1a	5	5	540 306	2 608 900 692	
150	180	open net	C1a	5	5	540 313	2 608 900 693	
150	220	open net	C1a	5	5	540 320	2 608 900 694	
150	240	open net	C1a	5	5	540 337	2 608 900 695	
150	320	open net	C1a	5	5	540 344	2 608 900 696	
150	400	open net	C1a	5	5	540 351	2 608 900 697	
125	80	open net	C0a	50	1	540 184	2 608 900 680	
125	100	open net	C0a	50	1	540 191	2 608 900 681	
125	120	open net	C0a	50	1	540 207	2 608 900 682	
125	150	open net	C0a	50	1	540 214	2 608 900 683	
125	180	open net	C0a	50	1	540 221	2 608 900 684	
125	220	open net	C0a	50	1	540 238	2 608 900 685	
125	240	open net	C0a	50	1	540 245	2 608 900 686	
125	320	open net	C0a	50	1	540 252	2 608 900 687	
125	400	open net	C0a	50	1	540 269	2 608 900 688	
150	80	open net	C0a	50	1	540 368	2 608 900 698	
150	100	open net	C0a	50	1	540 375	2 608 900 699	
150	120	open net	C0a	50	1	540 382	2 608 900 700	
150	150	open net	C0a	50	1	540 399	2 608 900 701	
150	180	open net	C0a	50	1	540 405	2 608 900 702	
150	220	open net	C0a	50	1	540 412	2 608 900 703	
150	240	open net	C0a	50	1	540 429	2 608 900 704	
150	320	open net	C0a	50	1	540 436	2 608 900 705	
150	400	open net	C0a	50	1	540 443	2 608 900 706	



BOSCH