




### TAH1RM-24

## Ratcheting Combination Wrench with Safety Spring 24 mm



### PRODUCT DETAILS

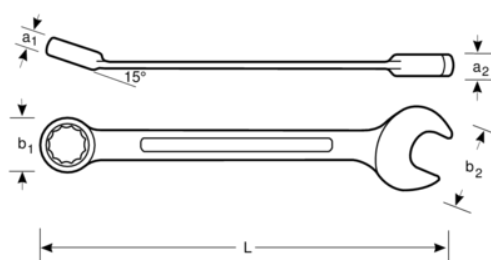

- Larger, bi-directional, size marking for easy identification
- 12-Point Dynamic-Drive™ profile provides longer life for screws and nuts
- Chrome micro-matte finishing
- High-performance alloy steel
- Offset and slim head to get more accessibility
- Ratchet in the ring for high productivity application
- Suitable for working at height
- Permanent stainless steel sliding spring maintains user ergonomics and full functionality
- Colour plates with maximum weight for a right matching with the lanyard
- According to DROPS best practices



Follow the Fish!



PRODUCT ATTRIBUTES

Product		<b>L</b>	<b>a1</b>	<b>a2</b>	<b>b1</b>	<b>b2</b>	
<b>TAH1RM-24</b>	24 mm	323 mm	14.5 mm	10.0 mm	46 mm	52 mm	550 g

