


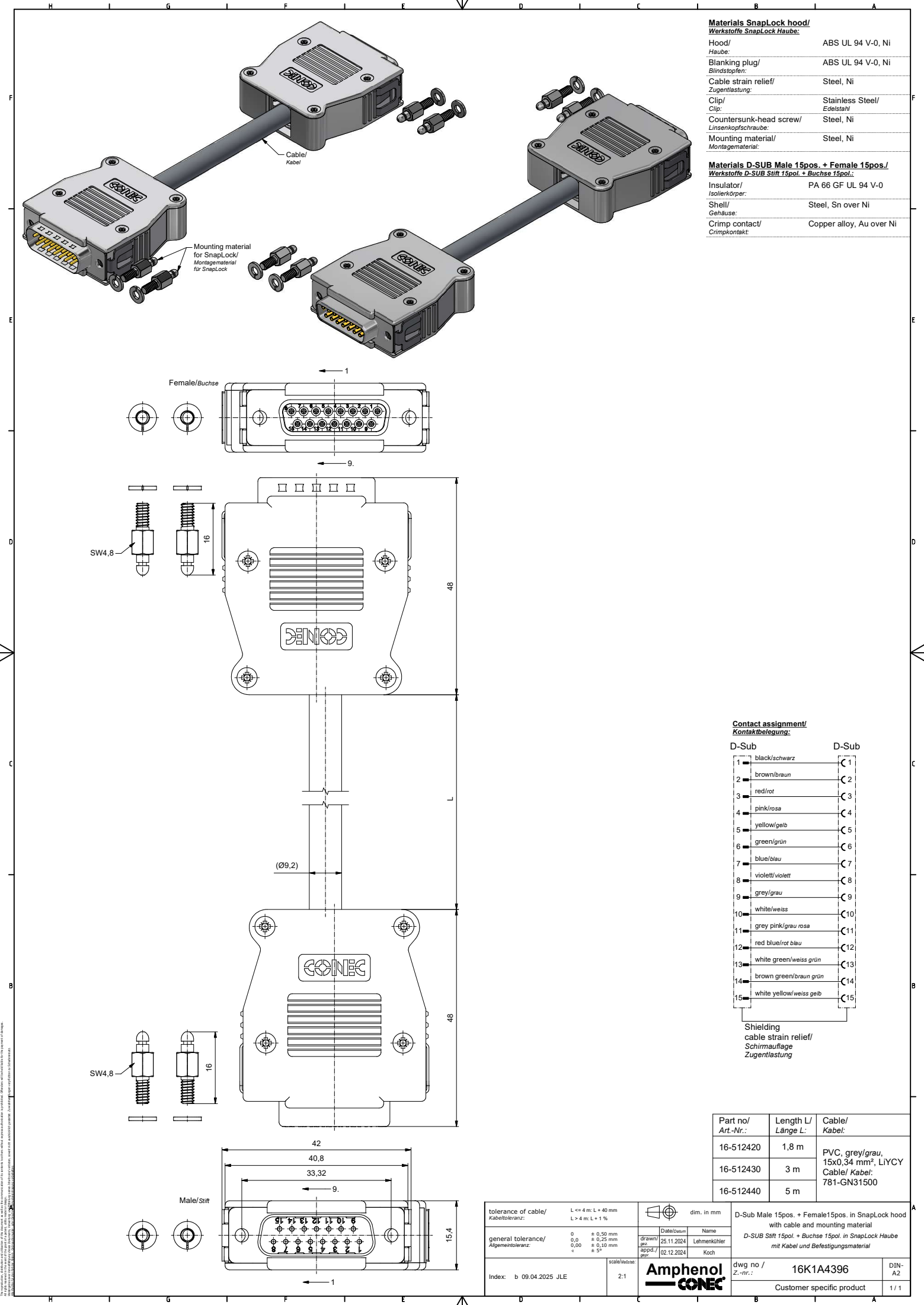

**Materials SnapLock hood/
Werkstoffe SnapLock Haube:**

Hood/ Haube:	ABS UL 94 V-0, Ni
Blanking plug/ Blindstopfen:	ABS UL 94 V-0, Ni
Cable strain relief/ Zugentlastung:	Steel, Ni
Clip/ Clip:	Stainless Steel/ Edelstahl
Countersunk-head screw/ Linsenkopfschraube:	Steel, Ni
Mounting material/ Montagematerial:	Steel, Ni

**Materials D-SUB Male 15pos. + Female 15pos./
Werkstoffe D-SUB Stift 15pol. + Buchse 15pol.:**

Insulator/ Isolierkörper:	PA 66 GF UL 94 V-0
Shell/ Gehäuse:	Steel, Sn over Ni
Crimp contact/ Crimpkontakt:	Copper alloy, Au over Ni

**Contact assignment/
Kontaktbelegung:**

D-Sub	D-Sub
1 black/schwarz	1
2 brown/braun	2
3 red/rot	3
4 pink/rosa	4
5 yellow/gelb	5
6 green/grün	6
7 blue/blau	7
8 violett/violett	8
9 grey/grau	9
10 white/weiß	10
11 grey pink/grau rosa	11
12 red blue/rot blau	12
13 white green/weiß grün	13
14 brown green/braun grün	14
15 white yellow/weiß gelb	15

Shielding
cable strain relief/
Schirmauflage
Zugentlastung

Part no/ Art.-Nr.:	Length L/ Länge L:	Cable/ Kabel:
16-512420	1,8 m	PVC, grey/grau, 15x0,34 mm², LiYCY
16-512430	3 m	Cable/ Kabel: 781-GN31500
16-512440	5 m	

tolerance of cable/ Kabeltoleranz:	L <= 4 m: L + 40 mm L > 4 m: L + 1 %	dim. in mm	Date/ Datum: 25.11.2024 Name: Lehmenkühler
general tolerance/ Allgemeintoleranz:	0 ± 0,50 mm 0,0 ± 0,25 mm 0,00 ± 0,10 mm ± 5°	drawn/ gezeichnet: 02.12.2024 approved/ genehmigt: Koch	dwg no / Z.-nr.: 16K1A4396
Index: b 09.04.2025 JLE	scale/ Maßstab: 2:1	D-Sub Male 15pos. + Female 15pos. in SnapLock hood with cable and mounting material D-SUB Stift 15pol. + Buchse 15pol. in SnapLock Haube mit Kabel und Befestigungsmaterial	
Amphenol CONEC		DIN-A2 Customer specific product 1/1	