

Pneumatic contact - HC-M-PN3-4,00-BU - 1663530

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)




Pneumatic socket, for HC-M-PN3 module, internal hose diameter of 4.0 mm



COMPLIANT

Key Commercial Data

| | |
|--------------------------------------|---|
| Packing unit | 10 pc |
| Minimum order quantity | 10 pc |
| GTIN |  4 017918 123345 |
| GTIN | 4017918123345 |
| Weight per Piece (excluding packing) | 0.650 g |
| Custom tariff number | 39174000 |
| Country of origin | United States |

Technical data

Ambient conditions

| | |
|---------------------------------|------------------|
| Ambient temperature (operation) | -40 °C ... 80 °C |
|---------------------------------|------------------|

Mechanical characteristics

| | |
|---|----------|
| Contact diameter | 5.2 mm |
| Operating pressure | 8.00 bar |
| Internal diameter of pressure hose connection | 4 mm |
| Insertion/withdrawal cycles | ≥ 500 |

General

| | |
|-------------------|-----------------|
| Series | HC-M-03-PN |
| Integrated valve | No |
| Color | black |
| Connection method | Hose connection |

Material data

Pneumatic contact - HC-M-PN3-4,00-BU - 1663530

Technical data

Material data


| | |
|------------------|---------------|
| Contact material | Delrin acetal |
|------------------|---------------|

Environmental Product Compliance

| | |
|------------|---|
| China RoHS | Environmentally friendly use period: unlimited = EFUP-e |
| | No hazardous substances above threshold values |

Drawings

Dimensional drawing

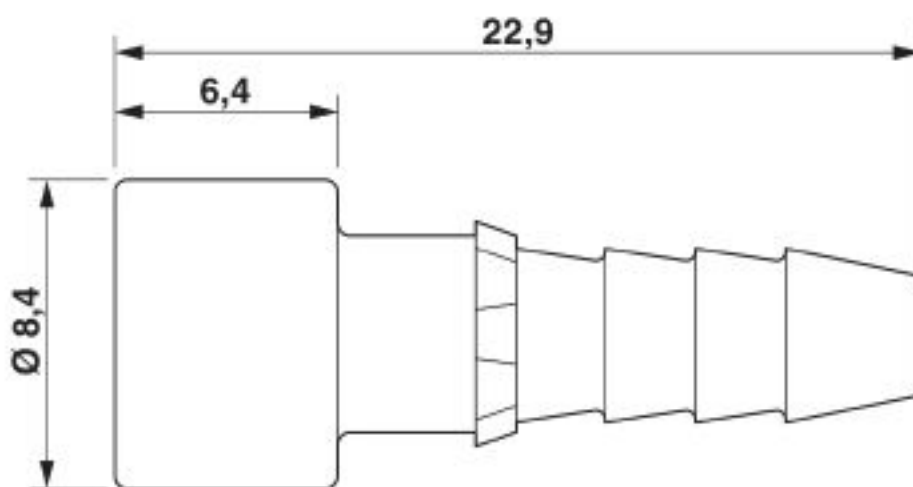

Classifications

eCl@ss

| | |
|---------------|----------|
| eCl@ss 10.0.1 | 27440192 |
| eCl@ss 4.0 | 27140800 |
| eCl@ss 4.1 | 27140800 |
| eCl@ss 5.0 | 27143400 |
| eCl@ss 5.1 | 27261200 |
| eCl@ss 6.0 | 27261200 |
| eCl@ss 7.0 | 27440205 |
| eCl@ss 8.0 | 27440205 |
| eCl@ss 9.0 | 27440192 |

ETIM

| | |
|----------|----------|
| ETIM 2.0 | EC000796 |
| ETIM 3.0 | EC000796 |
| ETIM 4.0 | EC000796 |
| ETIM 5.0 | EC000438 |
| ETIM 6.0 | EC000438 |

Pneumatic contact - HC-M-PN3-4,00-BU - 1663530

Classifications

ETIM

| | |
|----------|----------|
| ETIM 7.0 | EC000438 |
|----------|----------|

UNSPSC

| | |
|---------------|----------|
| UNSPSC 6.01 | 30211808 |
| UNSPSC 7.0901 | 39121408 |
| UNSPSC 11 | 39121408 |
| UNSPSC 12.01 | 39121408 |
| UNSPSC 13.2 | 39121522 |
| UNSPSC 18.0 | 39121421 |
| UNSPSC 19.0 | 39121421 |
| UNSPSC 20.0 | 39121421 |
| UNSPSC 21.0 | 39121421 |

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approval details

| | | |
|-----|--|--------------------------|
| EAC | | RU C- DE.AI30.B.01102 |
|-----|--|--------------------------|

Accessories

Accessories

Pneumatic insert, modular

Contact insert module - HC-M-03-PN-M-F - 1417433



Contact insert module, number of positions: 3, Socket, Pin, application: Pneumatics, for internal hose diameter of 1.6 / 3 / 4 mm

Pneumatic contact - HC-M-PN3-4,00-BU - 1663530

Accessories

Gasket - HC-M-PN3-ERSORI - 1408203



Replacement O-ring for HC-M-PN3...ST pneumatic pin contacts

Additional products

Pneumatic contact - HC-M-PN3-4,00-ST - 1663501



Pneumatic pin, for HC-M-PN3 module, internal hose diameter of 4.0 mm
