

Actuator

704.642.1

Distribution by
Rs-online<https://rs-online.eao.com/p/704.642.1>

Your product:



704.642.1 Actuator

FRONT

Front dimension: Ø 29 mm

Front form: Round

MOUNTING

Design: Raised

Mounting type: Panel mounting

ELECTRICAL CHARACTERISTICS

Standards: The switches comply with the "Standards for low-voltage switching devices" DIN EN 60947-1

MECHANICAL CHARACTERISTIC

Weight: 0.02 kg

AMBIENT CONDITION

IP Protection: IP65 front side

Operating temperature: – 40 °C ... + 55 °C

Storage temperature: – 40 °C ... + 85 °C

CERTIFICATE

REACH: REACH compliant

RoHS: RoHS compliant

OTHER

Short Description:

Actuator, Ø 29 mm, Round

Housing colour:

Grey


Housing material:

Plastic


Product attributes:

With series resistor for 220/240 V and filament lamp 130 V, 20 mA

Wiring diagrams:

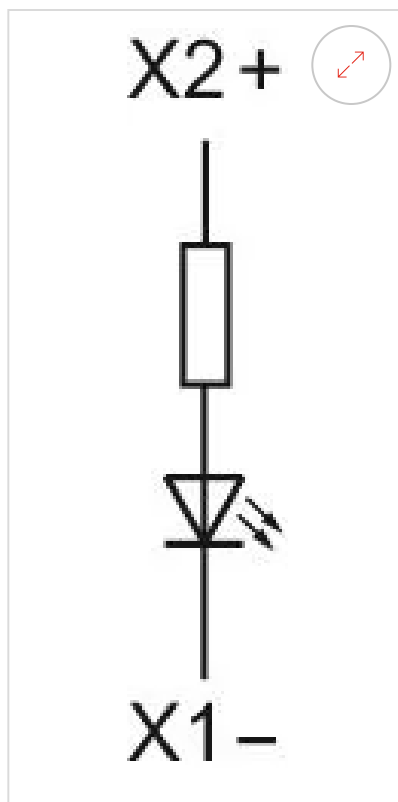

Mounting cut-outs:

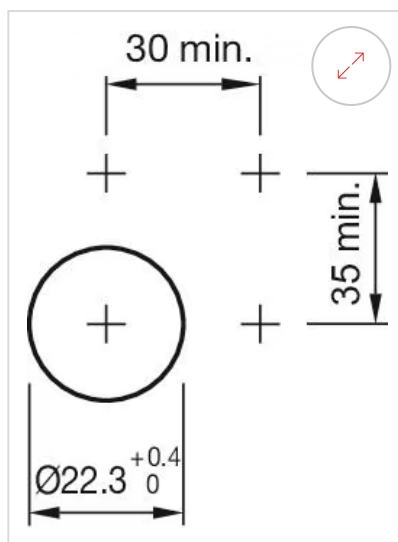

Dimension drawings:

