




FEATURES

- Coated
- 316 / 316 L grade
- Self Locking
- Rust Free
- Low Insertion force
-
-

RS PRO cable tie

RS Stock No.: 547-4349

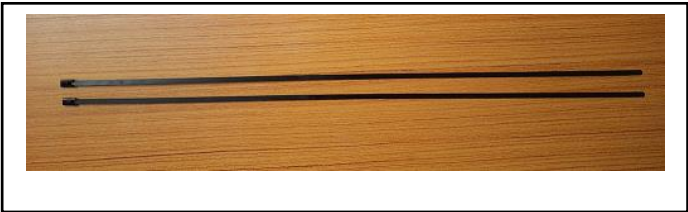

Product Description

Roller Ball Cable Tie

Coated

SS520C

Our products bring to you professional product categories. Our product range meets the highest standards and provides a comparable quality without paying a premium price.

Stainless Steel Cable Ties

Applications :

- *Installation of Cables and Pipes in Extreme conditions and Hazardous area.*
- *Petrochemical, food processing industries, power stations, mining, shipbuilding, offshore and other aggressive environments.*

Mechanical Specifications:

Width [mm]	4.6
Thickness [mm]	0.33
Length/s [mm]	520
Loop Tensile Strength	778 N
Operating Temperature [max]	165° C
Operating Temperature [min]	-60 °C
UV Resistant	Yes
Coated	Yes

Electrical Specifications

--	--

Protection Category

--	--

Classification

Stainless Steel Cable Ties

eCI@ss (Version)	
UNSPSC (Version)	

Approvals

Declarations	MFR Declaration of Conformity
Hazardous Area Certification	ATEX / IECEx
Standards Met	UL 62275 ; IEC 62275

Similar Products

Stock No.	Brand	Product Name	Attribute 1	Attribute 2	Attribute 3
XXX-XXXX	RS PRO				
XXX-XXXX	RS PRO				

Connection Diagrams / Assembly Diagrams / Illustrations / Accessories