


Tangential blowers

QLK 45 with double housing

- impeller diameter 45 mm
- horizontal mounting position
- permissible ambient temperature 0 - 60°C
- insulation class B, class F or H on request

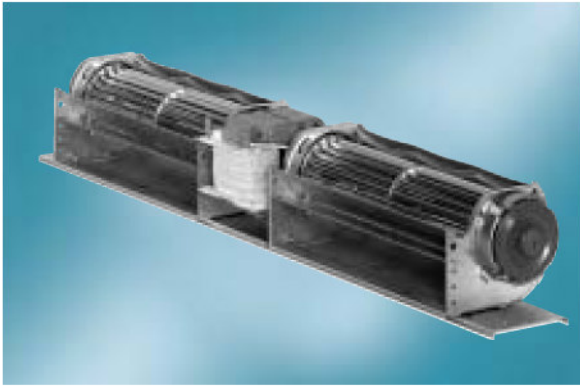

ebm-papst • Landshut

Nominal data	characteristic curve	rated voltage	frequency	air flow	max. pressure increase	power input	rated current	speed	mass	Dimensions mm				
										type	V	Hz	m ³ /h	Pa
QLK45/1212-3030	①	230	50	160	55	29	250	2300	1,85	372	81	122	375	390
QLK45/1818-3030	②	230	50	220	59	32	265	2200	2,15	492	81	182	495	510
QLK45/2424-3038	③	230	50	330	64	46	385	2000	2,40	620	89	242	620	635
QLK45/3030-3038	④	230	50	400	64	48	390	1700	2,60	740	89	302	740	755

Technical data valid at free air flow and rated voltage; bold print = standard type; subject to alterations

Characteristic curves

