



PBS20-XL

Plummer block housing unit

Plummer block housing units PBS, sheet steel housing, radial insert ball bearing with eccentric locking collar, P seals

X-life

Technical information

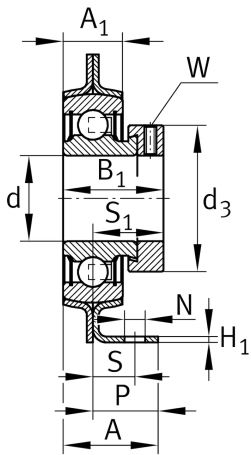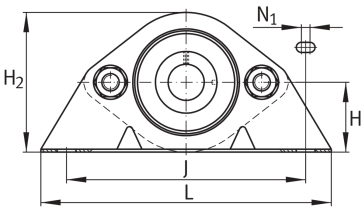

Your current product variant

Material Steel sheet

Main Dimensions & Performance Data

d	20 mm	Bore diameter
H 2	66.8 mm	Height
L	127 mm	Length total
C 0r G	3,200 N	Load carrying capacity (housing)
≈m	0.42 kg	Weight

Mounting dimensions

J	97 mm	Distance fixing bore
N	10.5 mm	Width (slot)
N 1	5.6 mm	Distance slot center
S	15 mm	Distance fixing

Dimensions

H	33.6 mm	Distance shaft axis
A	33 mm	Width (base)
A 1	15.8 mm	Width (head)
H 1	3 mm	Heigth (base)
P	25.4 mm	Distance support



Additional information

GEH47-PBS	Housing
RAE20-XL-NPP-B	Bearing designation

Temperature range

T _{min}	-20 °C	Operating temperature min.
T _{max}	120 °C	Operating temperature max.