

**BOSCH**

Invented for life

Product data sheet

Power tools for trade & industry

Rotary Hammer with SDS plus

PRO GBH 2-28



Strongest rotary hammer performance in Bosch 2 kg SDS plus category

The most important data

Rated input power	880 W
Impact energy	3.2 J
Drilling dia. concrete, hammer drill bits	4 – 28 mm

Part Number 0 611 267 571

Technical data

Performance data

Impact rate at rated speed	0 – 4,000 bpm
Rated speed	0 – 900 rpm

Technical data

Tool holder	SDS plus
Impact energy	3.2 J
Rated input power	880 W
Weight	3 kg
Packaging dimensions (width x length x height)	357 x 447 x 151 mm
Voltage, electrical	230 V

Drilling range

Drilling dia. concrete, hammer drill bits	4 – 28 mm
Opt. appl. range concrete, hammer drill bits	8 – 16 mm
Drilling diameter in concrete with core cutters	68 mm

Drilling range

Drilling dia. concrete, hammer drill bits	4 – 28 mm
Opt. appl. range concrete, hammer drill bits	8 – 16 mm
Drilling diameter in concrete with core cutters	68 mm

Drilling range

Drilling dia. concrete, hammer drill bits	4 – 28 mm
---	-----------

Opt. appl. range concrete, hammer drill bits	8 – 16 mm
Drilling diameter in concrete with core cutters	68 mm

Noise/vibration information

Hammer drilling in concrete

Vibration emission value ah	11 m/s ²
Uncertainty K	1.5 m/s ²

Chiselling in concrete

Vibration emission value ah	8.1 m/s ²
Uncertainty K	1.5 m/s ²



BOSCH


Invented for life

Product data sheet

Power tools for trade & industry

Advantages:

- Delivers 3.2 J of impact energy for high-power drilling performance
- KickBack Control for increased user protection
- Vibration Control for effortless and continuous work in time-intensive applications

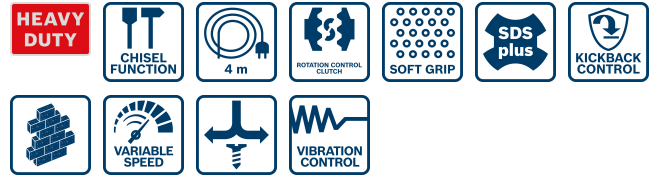

You can find more information about the deviations in the following link: <https://www.bosch-professional.com/gb/en/wac/>

