




RS 库存号 517-3709  
 RS 库存号 517-3715  
 RS 库存号 517-3721  
 RS 库存号 517-3737  
 RS 库存号 517-3771  
 RS 库存号 517-3793  
 RS 库存号 517-3800  
 RS 库存号 517-3759  
 RS 库存号 517-3765  
 RS 库存号 517-3743

## IP65 法兰高温箱（无密封、无涂层）

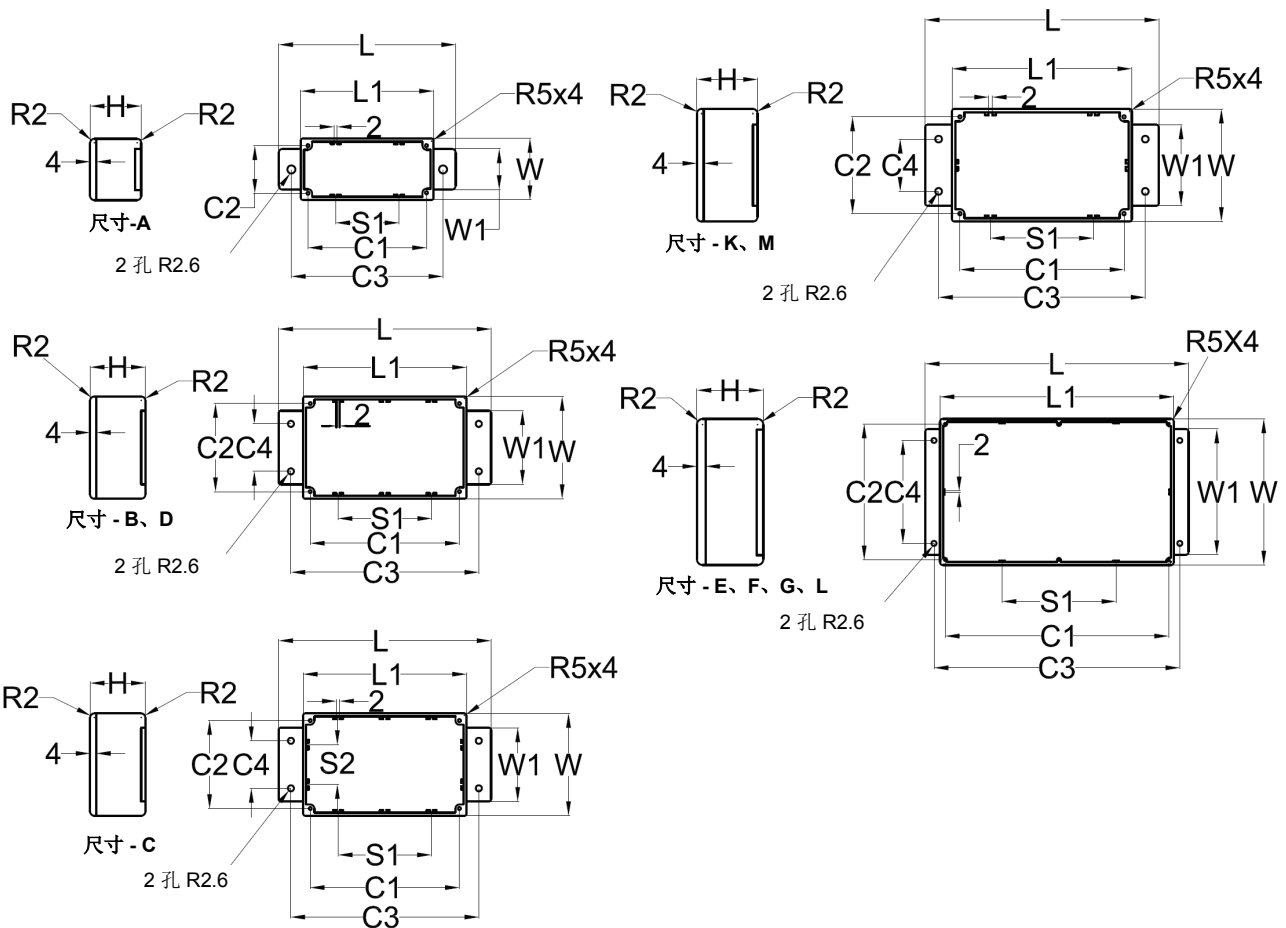

RS 库存号	尺寸号	L	L1	W	W1	H	C1	C2	C3	C4	S1	S2	壁厚
5173709	A	113.9	89.1	35.1	25.0	30.0	79.6	25.4			36.0		1.5mm
5173715	B	139.7	114.6	63.8	44.7	30.0	104.5	54.2	127.0	30.0	60.1		1.5mm
5173721	C	139.8	114.6	89.7	68.9	55.2	104.5	79.6	127.0	50.0	50.1	36.1	1.5mm
5173737	D	139.6	114.6	63.8	44.9	55.0	104.6	54.3	127.1	30.0	60.1		2mm
5173771	E	201.7	172.2	121.2	100.1	55.3	160.6	109.5	189.0	80.0	80.0		2mm
5173793	F	201.7	172.1	121.2	100.2	105.4	160.6	109.5	188.9	80.0	80.0		2mm
5173800	G	252.0	222.3	146.1	117.7	55.5	211.7	135.6	238.0	98.0	100.1		2mm
5173759	K	168.7	139.3	101.6	79.0	76.5	128.8	90.9	157.1	60.1	65.0		2mm
5173765	L	194.8	165.6	127.4	100.0	76.3	154.1	116.1	182.2	80.0	78.0		2mm
5173743	M	149.8	120.1	100.2	80.0	35.6	108.2	88.3	137.0	60.0	45.2		2mm

1. 基座和盖子材料：铝合金 ADC12
2. 螺钉材料：不锈钢 M3.5x9mm Supadrive 埋头
3. 表面：纯色本色
4. 每侧盖至底座的锥形角为 1.5°