




LED FIL Night Sensor A60 E27 4W (35W) 400lm 827 Clear

Article number: 141864

BAI LED Filament Sensor GLS A60 E27 4W 2700K Clear 400lm (35W) 230V-240V 320° 60x105mm Day / Night Lux Sensor LED-lamp

LED filament lamp with a day/night sensor. The base of the lamp has a sensor that reacts to the light (not on artificial light). At dusk (<20 lux), the lamp switches on and as soon as the light reappears, the lamp goes into sleep mode. You can therefore just leave the lamp "on" and never have to think again "would I have left the lamps on"? This makes this LED lamp even more energy efficient and sustainable than it already is.

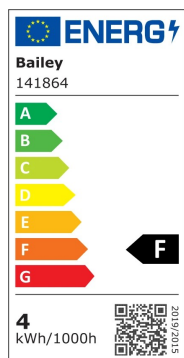

General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED FIL Night Sensor A60 E27 4W (35W) 400lm 827 Clear
Brand	Bailey
Productseries	LED Filament sensor
Producttype	A60 E27 827 CL SENSOR

ETIM specifications

Socket	E27
Luminous flux [lm]	400 - 400
Nominal voltage [V]	220 - 240
Lamp power [W]	4 - 4
Colour temperature [K]	2700 - 2700
Diameter [mm]	60
Length [mm]	105
Dimmable	No
Lamp shape	Pear-shape
Beam angle [°]	320 - 320
Colour	White
Type of glass/cover	Clear
Lamp designation	A-type
Colour rendering index CRI	80-89
Voltage type	AC
Filament lamp	Yes
Rated luminous flux according to IEC 62612 [lm]	400
Power factor	0.5
Lamp efficacy [lm/W]	100
Nominal current [mA]	38 - 38
Colour of light according to EN 12464-1	Warm white < 3300 K
Housing colour	Colourless
Average nominal lifetime [h]	15000
Degree of protection (IP)	IP20
Colour consistency (McAdam ellipse)	SDCM6
Min. number of switching cycles	12500
Weighted energy consumption in 1000 hours [kWh]	4
Remote operation possible	No
With movement sensor	No
With remote control	No
Photobiological safety according to EN 62471	RG0
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	No
Dimming phase cut-off (trailing edge)	No
Dimming phase cut-on (leading edge)	No
Dimming Touch and Dim	No
Dimming Zigbee	No

Dimming Bluetooth	No
Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	F
With twilight switch	Yes
Material of light bulb	Glass

Alternative articles



141866

LED FIL Night Sensor ST64 E27
4W (35W) 400lm 827 Clear

145579

LED Fil Night Sensor A60 E27
4W (40W) 470lm 827 Clear

Complementary articles



141964

Bulkhead AHOI E27 Alu Bronze
Oval IP64

141965

Bulkhead AHOI E27 Alu Nickel
Oval IP64