



Brand of NTN corporation

## Technical data

### ESFEE210

Bearing units




Grey cast housing, radial insert ball bearing with eccentric locking collar, single lip seal

### KIT CONTENT

ES210G2, FEE210

### VISUAL (S)

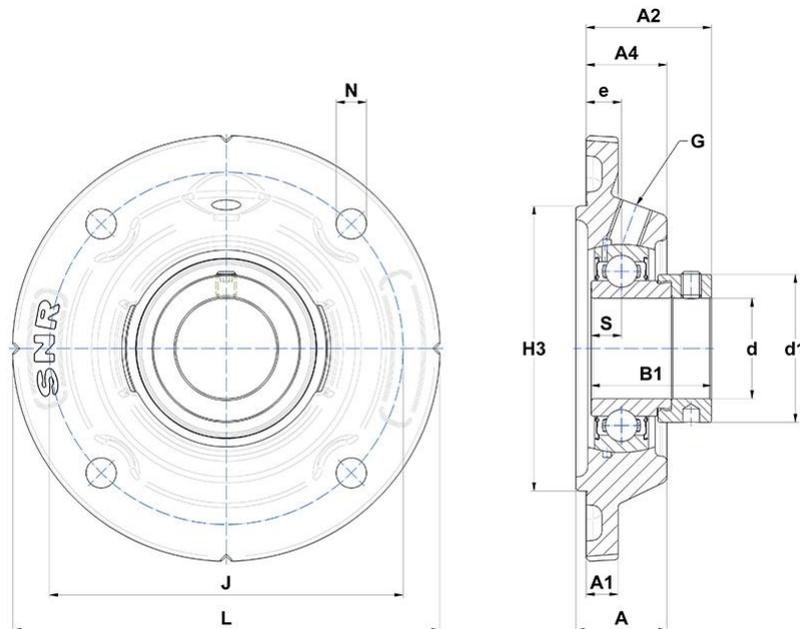

### PRODUCT DEFINITION

<b>Brand</b>	SNR
<b>A - Housing height</b>	32,5 mm
<b>A1 - Housing foot height / flange height</b>	13 mm
<b>A2 - Total height from mounting surface</b>	45,2 mm
<b>A4 - Housing height from mounting surface</b>	28,5 mm
<b>B - Width of Inner Ring</b>	30,2 mm



**NTN Europe**

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00  
 S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072  
 SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

**PRODUCT DEFINITION**

<b>B1 - Overall width Inner Ring</b>	43,7 mm
<b>d - Shaft diameter</b>	50 mm
<b>d1 - Outer dia of eccent. Lock. collar / nut of adapter sleeve</b>	67,2 mm
<b>e - Distance mounting surface to bearing center</b>	12,5 mm
<b>G - Grease fitting</b>	R1/8"
<b>H3 - Centering dia</b>	115 mm
<b>J - Mounting holes distance</b>	136 mm
<b>L - Housing width / diameter</b>	165 mm
<b>N - Mounting hole dimension</b>	14 mm
<b>S - Distance front side/bearing centre</b>	11 mm

**PRODUCT PERFORMANCE**

<b>C - Dynamic load rating</b>	35100000 mN
<b>C0 - Static load rating</b>	23200000 mN
<b>Operating temperature min.</b>	253,15 °K
<b>Operating temperature max.</b>	373,15 °K

**OTHER FEATURES**

<b>Mass</b>	2,5 kg
<b>Recommended tightening torque for set screw</b>	11.5 N-m

