

Professional wall distributor

16/16 RCB/circuit breaker

Item-no.: 0530x0001000



Robust and shockproof cover made of high-quality ABS plastic

Easy wall installation

Protective switchgear below lockable, shockproof cover made of polycarbonate

Sockets with self-closing hinge lids made of shockproof polyamide 6

Features: sockets with hinge lids 4 x 16A/230V, 2 x 16A/400V

Safety (ABB): 1 x circuit breaker 3 pole, 2 x circuit breaker 1 pole, RCB 40A/400V type A 30mA


Input via cable gland PG M32 from the top (blind gland M32 on the bottom)

Made in Germany, 100% checked, with serial number, testing protocols available

5 years manufacturer warranty


BGI-GUV-I608 compliant (K2)

Protection class: IP 54

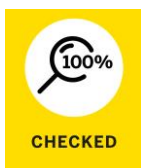

Professional wall distributor

Technical data

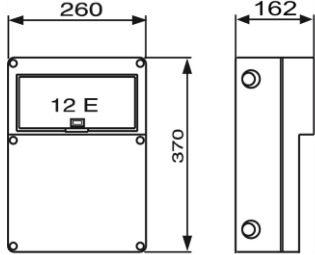Output: 2 x CEE 16 A, 400 V~ 4 x socket (type F) 230 V~	Safety: 1 x circuit breaker 16 A, 3-pole, C 2 x circuit breaker 16 A, 1-pole, C with RCB-switch 40 A, type A, 400 V~, 4-pole, 0,03 A via all outputs	
Input: Cable gland M32 on the top (blind gland M32 on the bottom) Weight: 4,715 kg Protection class: IP54 Protection degree: II Customized versions on request.	  	
Item-no. 0530x0001000 EAN 4012096012511 PU 1	370 x 260 x 162 mm Dimensions (L x W x H)	