


Kensington W2050 Pro 1080p Auto Focus Webcam

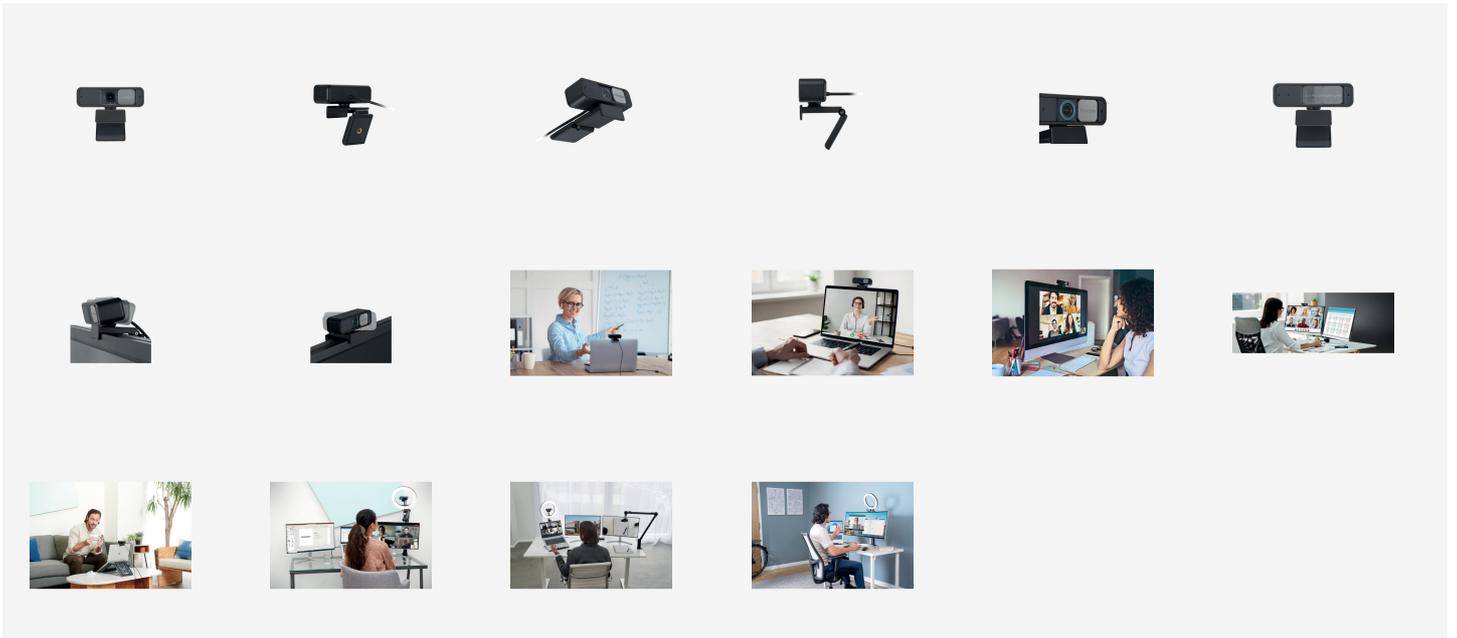

Kensington's W2050 Pro 1080p Auto Focus Webcam provides a wide field of view to accommodate multiple participants, adding the professional touch to today's video conferencing applications. Optimised to showcase you, your team or your background, the W2050 delivers high-quality video (1080p @ 30fps), dynamic zoom, two omnidirectional stereo microphones, flexible camera placement and enhanced low light imaging. Host a meeting, highlight your location, present a whiteboard or conduct a product demo. Be a part of Kensington's Professional Video Conferencing ecosystem - an elevated experience that empowers you to spend more time collaborating and less time troubleshooting. The W2050 provides a powerfully flexible experience on Microsoft Teams, Google Meet, Zoom and more.



Attributes

- The 93° diagonal field of view is ideal for team meetings, lectures or presenting products - the integrated lens cover allows you to control when you are seen.
- Glass lenses deliver high-quality video at 1080p (1920x1080 @ 30fps) with automatic focus, together with a large sensor for enhanced low-light performance.
- Customise your video settings at the click of a button. Use Kensington Konnect™ to optimise your focus, lighting and experience in any setting.
- Manually adjust your webcam up to 37° vertically and 360° horizontally to ensure the best camera angles. Take control with electronic pan, tilt and 2x zoom (ePTZ) to showcase you, your products or your team.
- Two omnidirectional stereo microphones with noise-reduction technology ensure you sound professional in every meeting and presentation.
- The W2050 accommodates both USB-A and USB-C devices such as laptops and desktops - so you can present like a pro on any device.
- Create a tailored Professional Video Conferencing setup based on your environment and budget by combining the W2050 with a Desktop Stand (K87651WW) and Ring Light (K87653WW) - and Kensington Konnect™ will bring it all together.
- Meets MIL-STD-810H Method 504.3 Contamination by Fluids with disinfectants with no degradation.* *No visual degradation or inability to use as directed upon test completion
- Connect with confidence knowing Kensington stands behind the W2050 with a 2-year warranty.

Specifications

Number	K81176WW
Colour	black
Dimensions (W x H x D)	54 x 48 x 89 mm
Weight	130 g
Pallet quantity	320
EAN code	85896811763