


ADDERLink EXTENDER BRACKET **DUAL**

Enables two AdderLink, AdderLink Silver or AdderLink Gold extenders to be rack-mounted in a 1U high enclosure

Local control will not be available on the ALS and ALG when used on this rackmount kit.


Options:
RMK-AL-DUAL

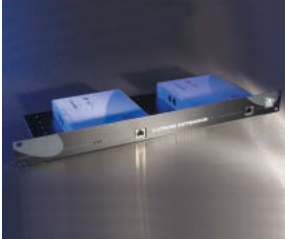

ADDERLink EXTENDER BRACKET **SINGLE**

Enables a single AdderLink, AdderLink Silver or AdderLink Gold to be rack-mounted in a 1U high enclosure

Options:
RMK-AL

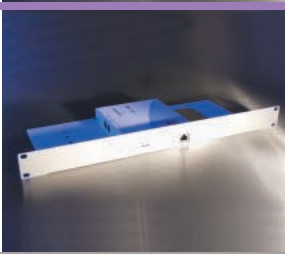

INTRODUCING...

ADDERLink **X** SERIES

The ultimate rackmount twisted pair KVM extension system

Please refer to the ADDER Link X-series brochure or www.addertec.com for more information



ADDERLink

CABLES

Adder cables are fully moulded individual coaxial cables for hi-resolution images. All cables are colour coded to PC99 specification and DDC compliant for today's plug and play monitors



Options:
VSCP5
(2m cable pack to connect IPC)

VSCP5-Gold
(As VSCP5 with audio)

ADDER Link

EXTENDER SERIES

www.addertec.com



ADDERLink EXTENDER SERIES

	ADDER Link	ADDER Link SILVER	ADDER Link GOLD
Remote Control KVM	✓	✓	✓
Local Control KVM	✓	✓	✓
RS232 port	✓	✓	✓
Maximum Resolution (at 75m)	1600x1280	1600x1280	1600x1280
Maximum Distance (at 1024x768)	200m	200m	200m
Audio Support	✓	✓	✓
Flash Upgrade	✓	✓	✓
Rack Mount	✓	✓	✓
Colour Compensation	✓	✓	✓
Reports Skew	✓	✓	✓
Max Rack Density	2/1u	2/1u	2/1u
Security Password	✓	✓	✓
Power/Activity Indication	✓	✓	✓
Fits into Rack Chassis	✓	✓	✓

SERIES

ADDERLink

X series KVM
X series GOLD
X series DUAL
X series SKEW

	X series KVM	X series GOLD	X series DUAL	X series SKEW
Remote Control KVM	✓	✓	✓	✓
Local Control KVM	✓	✓	✓	✓
RS232 port	✓	✓	✓	✓
Maximum Resolution (at 75m)	1600x1280	1600x1280	1600x1280	1600x1280
Maximum Distance (at 1024x768)	200m	200m	200m	200m
Audio Support	✓	✓	✓	✓
Flash Upgrade	✓	✓	✓	✓
Rack Mount	✓	✓	✓	✓
Colour Compensation	✓	✓	✓	✓
Reports Skew	✓	✓	✓	✓
Max Rack Density	16/2u	16/2u	16/2u	16/2u
Security Password	✓	✓	✓	✓
Power/Activity Indication	✓	✓	✓	✓
Fits into Rack Chassis	✓	✓	✓	✓



ADDER Technology Ltd
Technology House
Trafalgar Way
Bar Hill • Cambridge
CB3 8SQ • UK

T +44 (0) 1954 780044
F +44 (0) 1954 780081
sales@addertec.com
www.addertec.com

www.addertec.com



WORLDWIDE LEADERS IN ROBUST KVM TECHNOLOGY

ADDER Link EXTENDER SERIES

AdderLink is the world leading KVM extender which provides access to a PC or KVM switch across up to 200 mtrs of CAT5/5e/6* cable.

Offering exceptional value for money, the AdderLink range supports video resolutions of up to 1600 x 1280. Serial RS232 is also featured as standard, making AdderLink ideal for 'touch screen' applications.

For installations requiring additional functionality, AdderLink Silver adds local KVM control plus an internal KVM switch at the remote receiver. AdderLink Gold really stands out from the crowd, with stereo audio support and microphone input.

* For Cat5e and 6 cables in excess of 25 mtrs, Adder Skew compensator may enhance video quality for some installations.



ADDER Link EXTENDER

AdderLink provides remote access to your PC or KVM switch across up to 200 meters of twisted pair network cable. AdderLink comes with a fully bi-directional RS232 port for touch screen and other serial applications.

Options:

ALTX/ALRX-EURO
ALTX/ALRX-UK
ALTX/ALRX-USA

Single Rackmount Kit
Dual Rackmount Kit
Cables : see reverse

- Only one CAT5 cable required to connect your keyboard, monitor, mouse and serial RS232 device
- Easily installed in minutes with no software to install or knobs to adjust for set-up
- High video quality at a resolution of up to 1600 x 1280

- Compatible with all major operating systems including DOS, OS/2, UNIX, MS Windows, NT, XP, ME, 2000, NetWare and RS6000



Need more information? visit www.addertec.com



ADDER Link SILVER

With local and remote control, fully bi-directional RS232 port, plus an integrated KVM switch at the remote location, the AdderLink Silver is the ideal solution for remoting a CPU and accessing a desktop PC.


Options:

ALSTX/ALSRX-EURO
ALSTX/ALSRX-UK
ALSTX/ALSRX-USA

Single Rackmount Kit
Dual Rackmount Kit
Cables : see reverse

- Local and remote KVM control
- Integrated KVM switch allowing a local computer to be connected at the remote location
- High Speed bi-directional RS232 serial port

- Compatible with all major operating systems including DOS, OS/2, UNIX, MS NT, MS Windows 2000, NetWare and RS6000

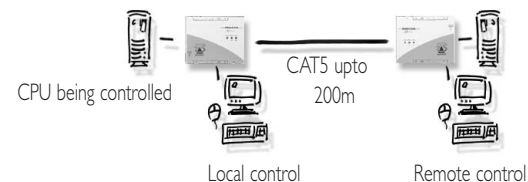

Need more information? visit www.addertec.com



ADDER Link GOLD

Providing local and remote KVM access, stereo audio, microphone, RS232 plus an integrated KVM switch in the remote unit. The complete KVM multi-media remoting solution, all across a single twisted pair cable.

Options:

ALGTX/ALGRX-EURO
ALGTX/ALGRX-UK
ALGTX/ALGRX-USA

Single Rackmount Kit
Dual Rackmount Kit
Cables : see reverse

- Stereo audio and microphone support
- Integrated KVM switch allowing a local computer to be connected at the remote location

- Local and remote KVM control
- High video quality at a resolution of up to 1600 x 1280



Need more information? visit www.addertec.com

