
6000 K

LEDriving T4W – Premium | LED – Interior lighting



Areas of application

- Interior lighting

Product benefits

- 5 year guarantee
- Perfect light distribution thanks to modern diffusor material
- Two different light colors for a variety of customization options
- Maintenance-free thanks to long lifetime of up to 5,000 h
- Up to 80 % less energy consumption (compared to standard lamps)
- Easy plug & play replacement

Product features

- LED retrofit lamps for various applications in vehicle interiors
- LEDT4W available with color temperature: 4,000 K, 6,000 K
- LEDT4W available with light color: Warm White, Cool White
- Shockproof and vibration-proof

Product datasheet

Technical data


Electrical data

| | |
|-----------------|--------|
| Power input | 1 W |
| Nominal wattage | 4.00 W |
| Nominal voltage | 12 V |
| Test voltage | 13.2 V |

Photometrical data

| | |
|-------------------|--------|
| Color temperature | 6000 K |
| Luminous flux | 50 lm |

Dimensions & weight

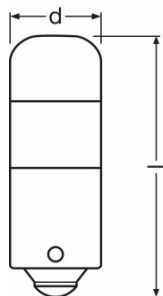

| | |
|----------|---------|
| Length | 27.4 mm |
| Diameter | 9.0 mm |

Lifespan

| | |
|-------------|--------|
| Lifespan B3 | 500 h |
| Lifespan Tc | 1000 h |

Additional product data

| | |
|-----------------------------|------|
| Base (standard designation) | BA9s |
|-----------------------------|------|

Certificates & standards

| | |
|--------------|---|
| ECE category | - |
|--------------|---|

Product datasheet

Logistical Data

| Product code | Product description | Packaging unit (Pieces/Unit) | Dimensions (length x width x height) | Volume | Gross weight |
|---------------|---------------------|------------------------------|--------------------------------------|----------------------|--------------|
| 4008321658111 | 6000 K | Blister 2 | 106 mm x 80 mm x 105 mm | 0.89 dm ³ | 98.00 g |
| 4008321658128 | 6000 K | Shipping carton box 10 | 104 mm x 108 mm x 395 mm | 4.44 dm ³ | 100.00 g |
| 4008321667205 | 6000 K | Shipping carton box 420 | 106 mm x 108 mm x 395 mm | 4.52 dm ³ | 494.00 g |

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

References / Links

Guarantee terms are available at

▶ www.osram.com/am-guarantee

Legal advice

Not ECE conform

Only approved for off-road use when used in an exterior application. Illegal use on public roads leads to cancellation of vehicle operating licence and loss of insurance cover.

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.
