
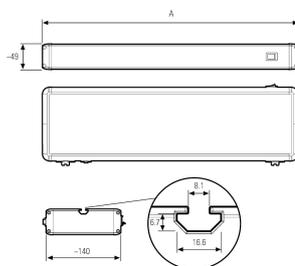
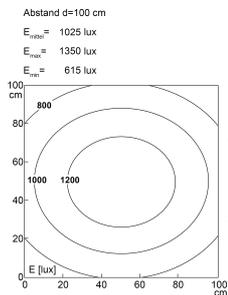


LED system light

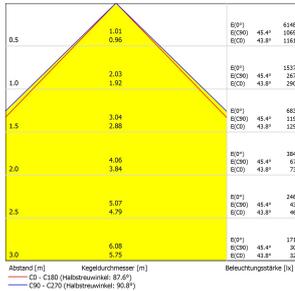

<b>Product-Nr.</b>	155110-02
<b>EAN:</b>	4260556627014
<b>Model:</b>	SYSTEMLED EVO - ECO Daylight White
<b>Order number:</b>	155110-02
<b>Model:</b>	SYSTEMLED EVO - ECO Daylight White
<b>Type:</b>	LED system light
<b>Illuminant:</b>	SMD LED
<b>Total output incl. driver:</b>	~26 W
<b>Power consumption:</b>	~23 W
<b>Lamp luminous flux:</b>	3980 lm
<b>Lamp luminous efficiency:</b>	173 lm/W
<b>Light distribution:</b>	direct
<b>Light colour:</b>	5700K 3-step MacAdam
<b>R9:</b>	90
<b>Connected load:</b>	120-277VAC, 50 - 60 Hz
<b>Power supply:</b>	integrated
<b>Connection (connector):</b>	Wieland GST18
<b>Degree of protection:</b>	IP40
<b>Class of protection:</b>	I
<b>Glare control:</b>	Microprisms
<b>Beam angle (optics):</b>	90°
<b>Operating temperature:</b>	-10 °C - +50 °C (14 °F - 122 °F)
<b>Storage temperature:</b>	-20 °C - +80 °C (-4 °F - 176 °F)
<b>Colour rendering (Ra):</b>	>90 (typ. 95)
<b>Lamps lifetime:</b>	> 100,000 h (L80/B10)
<b>Housing material:</b>	aluminum and PMMA
<b>Height [B] x Width [C]:</b>	48 mm x 139 mm (~1,89" x ~5,47")
<b>Length [A]:</b>	898 mm (~35,35")
<b>Mounting:</b>	T-slot rear (8 mm)
<b>Weight (net):</b>	2550 g (~90 oz)
<b>Gross weight:</b>	3410 g (~120 oz)
<b>Risk group (DIN EN 62471):</b>	free group
<b>Markings:</b>	CE, UKCA
<b>Dimmable:</b>	yes
<b>Mounting accessories:</b>	optional
<b>Made in:</b>	Germany
<b>Feature:</b>	externally dimmable/switchable