

## Datasheet

# RS White Hookup Wire, UL1213, 600 V RoHS Compliant, UL AWM STYLE 1213 105C, UL Style 1213

RS Stock number 813-3498



### Product Description

**Application:**

general application and according to customer

 
**Multi-construction**

Single

### Construction

<b>Single</b>	<b>Silver Plated Copper</b>
AWG	22
Construction	0.15±0.005x19
Stranded Dia.(mm)	0.75
<b>Jacket</b>	<b>PTFE</b>
Nom. Thickness (mm)	0.27
Jacket Dia.(mm)	1.30±0.1
Jacket Color	See Table 1

**Marking(Color see table 1,3times/Per meters)(height:>=0.4mm)**


Exxxxxx  AWM STYLE 1213 105C VW-1

22 AWG ROHS

**PACKAGING**

100m reel

## Design

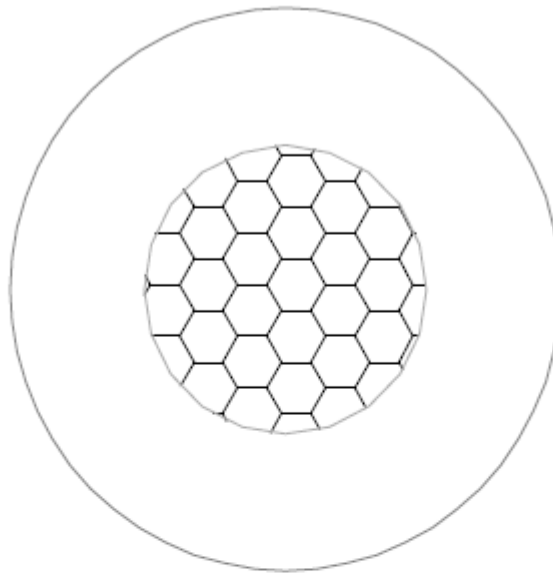

### Electrical Characteristics

Max.Conductor DC Resistance at 20°C ( $\Omega$ /Km)	55
Rated Temperature(°C)	-60 to 200C
Rated Voltage(V)	600
20°C Insulation Resistance(M $\Omega$ .KM)	> 200
UL	AWM 1213
Mil Spec reference	MIL-W-16878E
Flame Compliance	UL VW-1
Reference	BS 3G 210 Type B