



Datasheet


ENGLISH

New 5.0mm Plug Straight 15A 5 way

RS Stock 874-4789



Dimensions: (mm)

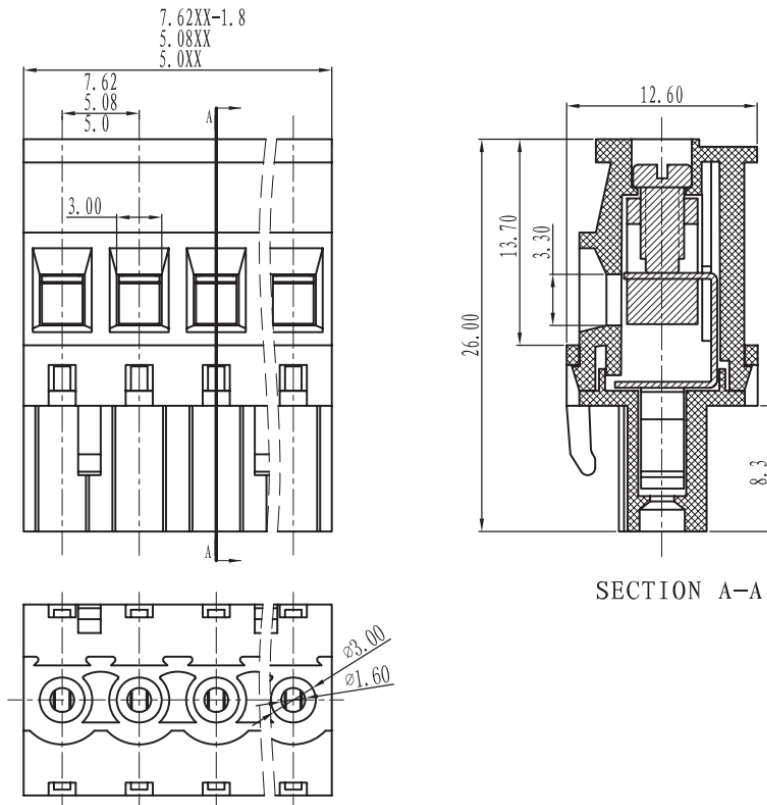



ENGLISH

Specifications

Electrical

Standard:	UL	IEC
Rated voltage:	300V	320V
Rated current:	15A	20A
Contact resistance:	20m Ω	
Wire range:	28-14AWG	2.5mm ²
Withstanding voltage:	AC2000V/1Min	
Insulation resistance:	500M Ω /DC500V	

Mechanical

Temp.Range:	-40° C~+105° C
Torque:	0.5Nm(4.51lb`in)
Strip length:	7-8mm

Dimensions

Pitch:	5.0mm, 5.08mm, 7.62mm
Poles:	02P-24P

Material

Housing:	PA66, UL94V-0
Screws:	M3, steel Zinc plated
Clamp:	Brass, Ni plated
wire guard:	Phosphor bronze, Ni plated