

## RIVETING PLIERS & RIVETS

- Heavy duty steel construction for exceptional strength & durability
- Colour coded interchangeable nose bushes for convenience (Nose spanner included)
- 3 jaw mechanism for increased grip and outstanding long term performance – 50% greater gripping strength than a standard 2 jaw riveter
- Ergonomic anti-slip handles for increased comfort



### Riveting pliers

Item Number	Length	Interchangeable nose bushes for setting	Quantity
T3820	260mm 10 1/2"	3.15mm (1/8"), 4mm (5/32"), 4.8mm (3/16") rivets	3


CONTENTS: Riveting pliers. 25 x aluminium rivets, sizes: 1/8" (3.2mm), 5/32" (4.0mm) & 3/16" (4.8mm).



### Riveting pliers set

Item Number	Quantity
T3820AS	1

- Heavy duty steel construction for exceptional strength & durability
- 'Anti shock' design protects from injuries to wrist, arm or shoulder
- Cushion grip handle for superior grip & comfort
- Colour coded interchangeable nose bushes for convenience

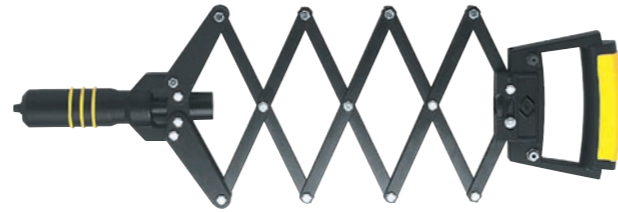

### Lazy tong riveter

Item Number	Length	Interchangeable nose bushes for setting	Quantity
T3822A	305 - 780mm 12" - 32 1/2"	2.4mm (3/32"), 3.15mm (1/8"), 4mm (5/32"), 4.8mm (3/16"), 6mm (1/4") rivets	1

- Colour coded for simple size identification



### Rivets - Aluminium (Pack 50)

Item Number	Length	Interchangeable nose bushes for setting	Quantity
T3819A 408	3.15 x 6mm 1/8 x 1/4"	short	15
T3819A 412	3.15 x 9mm 1/8 x 3/8"	medium	15
T3819A 415	3.15 x 12mm 1/8 x 1/2"	large	15
T3819A 508	4 x 6mm 5/32 x 1/4"	short	15
T3819A 512	4 x 9mm 5/32 x 3/8"	medium	15
T3819A 515	4 x 12mm 5/32 x 1/2"	large	15
T3819A 612	4.8 x 9mm 3/16 x 3/8"	medium	15
T3819A 615	4.8 x 12mm 3/16 x 1/2"	long	15
T3819A 620	4.8 x 16mm 3/16 x 5/8"	ex long	15

- Galvanised steel for corrosion resistance



### Washers - (Pack 100)

Item Number	Length	Quantity
T3824 12	3.15mm 1/8"	15
T3824 15	4mm 5/32"	15
T3824 18	4.8mm 3/16"	15

CONTENTS: 3 x riveting pliers. 3 x riveting pliers sets. 6 x boxes of aluminium rivets (x9 sizes). 6 x boxes of washers (x3 sizes).



### Riveting display stand

Item Number	Dimensions	Quantity
T3825LS	570 x 530 x 330mm	1

## PVC CUTTERS

- Heavy duty aluminium body - Strong & light
- Ratchet action razor sharp stainless steel blade for effortless cutting of; PVC conduit, blue water mains, plastic pipe, rubber hose, pneumatic pipe, electrical sleeving, etc
- Complete with special adaptor for straight or mitre cutting of small rectangular cross-section trunking



### PVC pipe & conduit cutter - Ratchet

Item Number	Length	Blade Width	Quantity
430003	220mm	32mm	3

- Glass fibre reinforced polycarbonate body - Strong & light
- Razor sharp stainless steel blade for efficient cutting of: PVC conduit, blue water mains, plastic pipe, rubber hose, pneumatic pipe, electrical sleeving, etc



### PVC pipe & conduit cutter

Item Number	Length	Blade Width	Quantity
430001	195mm	28mm	3

- Heavy duty aluminium body - Strong & light
- Lever action razor sharp stainless steel blade for effortless cutting of; PVC conduit, blue water mains, plastic pipe, rubber hose, pneumatic pipe, electrical sleeving, wooden dowel, etc
- 5 interchangeable anvils (flat, double radius, single radius, 90° square and mitre) allow a variety of cross sections to be cut, both straight and mitred



### Multi cutter set

Item Number	Quantity
T2240	3