

Data sheet Product SL 2 104 72 Z




PCB connectors>Male headers
two rows, $\square$ 0.635 mm

Features

pitch:	2.54 x 2.54 mm
no. of contacts:	72
contact material:	CuSn-alloy
surface of contact:	tin-plated
surface contact / contact sleeve:	• Ni+$\geq 0.2\mu\text{m}$ Au • Ni+4...6μm Sn
version:	standard
volume resistance:	$\leq 5\text{ m}\Omega$
nominal current:	3 A
nominal voltage:	250 V AC
test voltage:	2000 V
insulating body material:	PA 4.6. GF
temperature range:	• -40°C... +163°C • (260°C/10 s)
class of inflammability:	UL 94 V-0
specific insulation resistance:	$>10^7\ \Omega\cdot\text{m}$
connection type:	THT (soldering)
reflow solderable:	yes

Technical Drawing

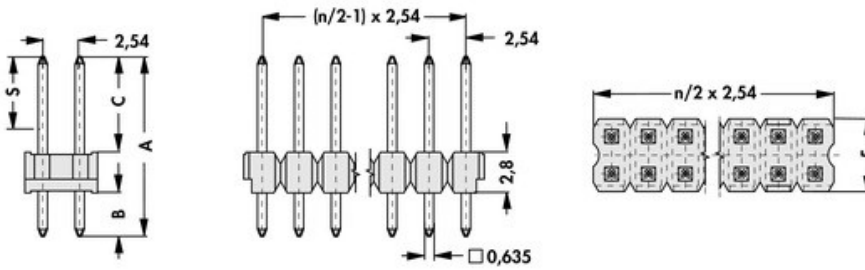

A:	19 mm
B:	5.8 mm
C:	10.4 mm
S:	5.0 mm

Fischer Elektronik GmbH & Co. KG
 DEUTSCHLAND • GERMANY • ALLEMAGNE

Nottebohmstraße 28
 58511 Lüdenscheid

Telefon +49 2351 435-0
 Telefax +49 2351 45754

info@fischerelektronik.de
 www.fischerelektronik.de