

Datasheet

RS Pro P13.5s Filament Indicator Lamp, Clear, 2.5 V, 300 mA, 10h

RS Stock No: **655-9053**



Product Details

RS Pro P13.5s filament indicator lamp comes with clear lens and P13.5s prefocus base. It is filled with Krypton gas for high brightness. It has a voltage rating of 2.5 V and current rating of 300 mA. The lamp has 10 h life.

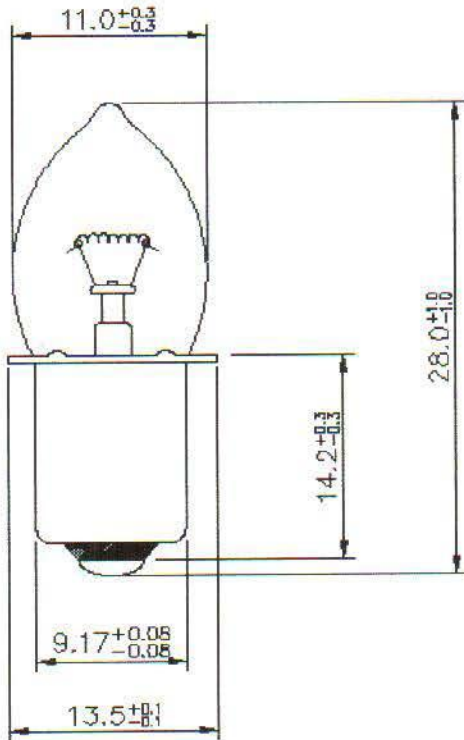
Features and Benefits

- Olive shape B3 1/2 - 11 mm glass
- P13.5s prefocus base
- Vacuum



Specifications:

Current Rating	300 mA
Diameter	11.3 mm
Lamp Base	P13.5s
Lamp Size	B3 1/2
Length	29 mm
Lens Colour	Clear
Life Hours	10 h
Luminosity	6 lm
Voltage Rating	2.5 V

RS Stock No.	6559053	
<i>DRAWING - I</i>		
	Unit : mm	
1. Structure	Bulb Type	B3 1/2
	Bulb Diameter	Ø 11.3Max.
	Length	29.0Max
	Base Type	P13.5s.
2. Design Characteristics	Voltage	2.5V
	Amperage	300mA±10%
	Luminous Flux	6Lm±20%
	Life Hours	10Hrs