



Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2025 (247) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 360033-1
090 DIA CLSTR BLK



TE Part # 7-2150942-7
OCEAN_2.0_SPARE_PART_KIT-070F130F



TE Part # 2150942-2
OCEAN_2.0_Applicator-E-070F130F-SEA




TE Part # 737110-3
CLUSTER BLOCK HSG VO WHI



TE Part # 62131-8
CLSTR PIN RCPT



TE Part # 141101-2
RECEPT CLUSTER

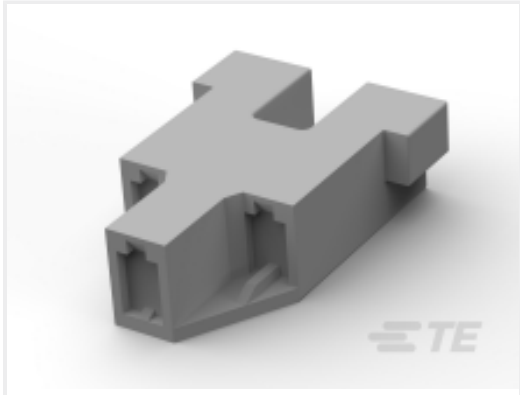

TE Part # 171370-5
CLUSTER BLOCK HSG PBT

Customers Also Bought



TE Part #170011-2
RING STRIP 18-14 MM2 0.503 X 11.938 TPBR



TE Part #1217175-1
CLUSTER BLOCK RECPT.




TE Part #62420-1
MAG-MATE TERM 20-22 016 TPBR




TE Part #62306-2
AMVAR SPLC 1500-5000 020TPBR




TE Part #1-2371464-2
2P, RAST5 P-LOCK HSG, INNER SLOT

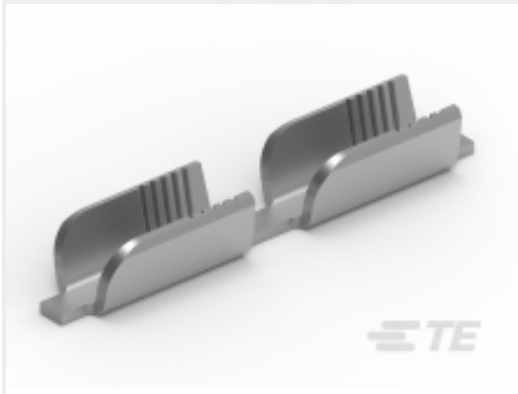

TE Part #2825180-2
FINE MAGWIRE SPLICE, MINI-MAG SERRATION

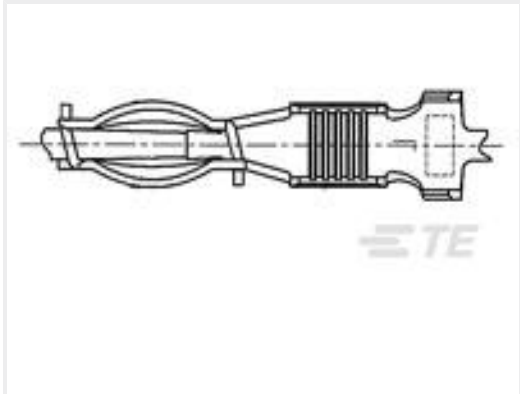


TE Part #353937-1
2.3 CLUSTER REC AMPLIVAR TYPE

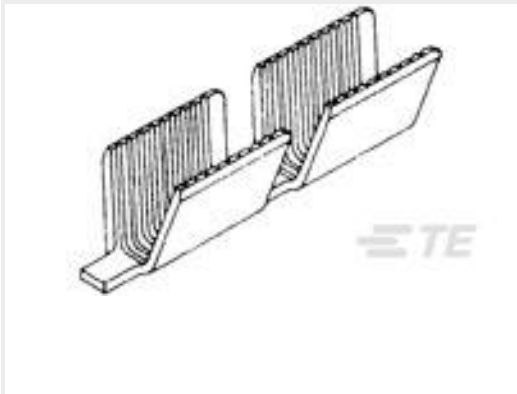

TE Part #62308-2
AMVAR SPLC 3000-7000 020TPBR



TE Part #5-1376382-1
5.0 POWER KEY CONNECTOR 2P HEA

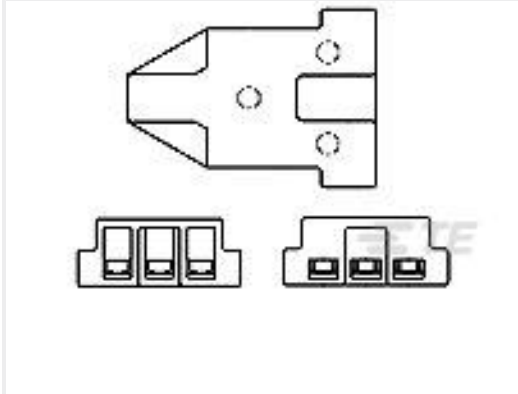

TE Part #171370-3
CLUSTER BLOCK HSG PBT

Documents



Product Drawings

2.3 DIA CLUSTER AMPLIVER S TIN

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_1123655-1_D_c-1123655-1-d.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_1123655-1_D_c-1123655-1-d.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_1123655-1_D_c-1123655-1-d.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

Application Specification

English