


FAST SANDING OF PAINT AND WOOD

EXPERT C470 Sandpaper

EXPERT

- ① Exceptional abrasion with Bosch Surface Structure
- ② Grain alignment during production ensures aggressive cut
- ③ Grain distribution optimised for high-speed sanding

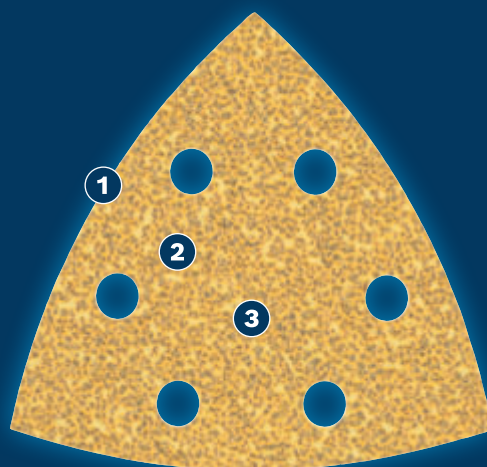

SURFACE
STRUCTURE

UP TO
2x*



* vs. Bosch C420




Video



BOSCH

EXPERT C470 SANDPAPER

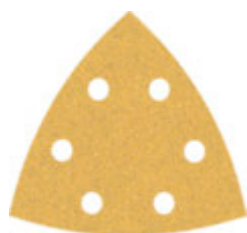

- ▶ Ideal for highly effective fast sanding of flat surfaces; to remove old paint; or to smooth, prepare and finish surfaces
- ▶ EXPERT Abrasives - the very best for all trades
- ▶ Up to 2x faster than Bosch C420 Sandpaper
- ▶ Just stick it on with hook and loop



PRODUCT PROPERTIES				ORDERING INFORMATION					
Sheet dimensions mm	Grit	Perforation	Packaging type	Pack quantity	Minimum order quantity	Barcode 4 059 952...	Part number		
93x93	40	6 holes	C1a	5	5	541 617	2 608 900 823		
93x93	60	6 holes	C1a	5	5	541 624	2 608 900 824		
93x93	80	6 holes	C1a	5	5	541 631	2 608 900 825		
93x93	100	6 holes	C1a	5	5	541 648	2 608 900 826		
93x93	120	6 holes	C1a	5	5	541 655	2 608 900 827		
93x93	180	6 holes	C1a	5	5	541 662	2 608 900 828		
93x93	240	6 holes	C1a	5	5	541 679	2 608 900 829		
93x93	320	6 holes	C1a	5	5	541 686	2 608 900 830		
93x93	400	6 holes	C1a	5	5	541 693	2 608 900 831		
93x93	40	6 holes	C0a	50	1	542 645	2 608 900 926		
93x93	60	6 holes	C0a	50	1	542 652	2 608 900 927		
93x93	80	6 holes	C0a	50	1	542 669	2 608 900 928		
93x93	100	6 holes	C0a	50	1	542 676	2 608 900 929		
93x93	120	6 holes	C0a	50	1	542 683	2 608 900 930		
93x93	180	6 holes	C0a	50	1	542 690	2 608 900 931		
93x93	240	6 holes	C0a	50	1	542 706	2 608 900 932		
93x93	320	6 holes	C0a	50	1	542 713	2 608 900 933		
93x93	400	6 holes	C0a	50	1	542 720	2 608 900 934		



BOSCH