

# LX Series

## Amaris A3 Laminator

Office (3-5 Users)

### Features:

- Ready to laminate in just 60 seconds with InstaHeat Technology
- Laminates an A4 pouch in under 30 seconds (800mm/min)
- 6-rollers for high quality results - laminates all pouches up to 175 microns (2x175)
- Individual temperature settings for laminating 80, 125 and 175 micron pouches
- Manual reverse for removing and re-aligning mis-fed pouches
- Clean Alert System enables consistent, high-quality results and optimum laminator performance
- Auto-Shut Off after 30 mins inactivity
- Includes 10-pouch laminating starter kit with cleaning sheet
- For best results, use Fellowes branded pouches




Exit Tray



### Specifications

|                                              |                 |
|----------------------------------------------|-----------------|
| Segment                                      | Office          |
| Format – Laminating Width                    | A3              |
| Pouch Thickness (mic)                        | 175 mic         |
| Heat up Time (min)                           | 1               |
| Number Rollers                               | 6               |
| Lamination Speed (cm/mn)                     | 80              |
| Laminates 1 A4 (sec)                         | 23              |
| Entry Width                                  | 320             |
| Colour                                       | White/Grey      |
| Product Dimensions (H x W x D) / mm          | 475 x 152 x 101 |
| Product Weight                               | 2.9 kg          |
| Retail Packaging Dimensions (H x W x D) / mm | 522 x 212 x 155 |
| Retail Packaging Weight                      | 3.5 kg          |
| Outer Carton Dimensions (H x W x D) / mm     | 535 x 225 x 170 |
| Outer Carton Weight                          | 3.7 kg          |
| Quantity per Outer Carton                    | 1               |
| Country of Origin                            | China           |
| Warranty                                     | 2 year          |

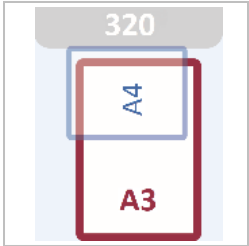

|           |         |                   |                     |
|-----------|---------|-------------------|---------------------|
| Code (EU) | 8058201 | UPC: 043859773824 | SCS: 50043859773829 |
| Code (UK) | 8058601 | UPC: 043859779253 | SCS: 50043859779258 |
| Code (CH) | 8058501 | UPC: 043859778577 | SCS: 50043859778572 |

#### Recommended


|                 |         |
|-----------------|---------|
| Cleaning Sheets | 5320604 |
| IL 80 Micron    | 5306114 |

# LX Series


## Amaris A3 Laminator

Office (3-5 Users)

### Recyclability:

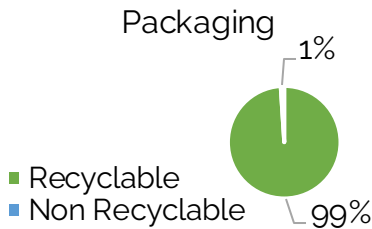

**Packaging Recyclability**  
Percentage of the packaging by weight that can be sent for recycling

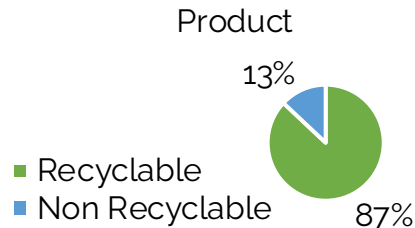

**Product Recyclability**  
Percentage of the product by weight that can easily be separated and sent for recycling

### Certifications:



### Other information:

**Servicing:** Relevant info about servicing the laminator (for example cleaning the rollers of the machine) can be found in the Product Manual.

#### After Sales Support:

- Repairable: NO
- Availability of Spare Parts: NO
- Returnable: Yes, as per Fellowes Trading Conditions

**Declaration of Conformity:** The declaration of conformity can be found on the back of the Product Manual that comes with the laminator.

Digital versions of the manual can be found on your local Fellowes.com website in the 'downloads tab' of this product

**Support:** This unit comes with a 2-year machine. For product related questions, or further information, our dedicated Customer Service team can be reached at our freephone number 00800 1810 1810