

ULTRA LIGHTWEIGHT MEDIUM CUT RESISTANT GLOVE WITH NITRILE FOAM.

A second skin cut resistant glove, thin, soft and comfortable allowing high dexterity tasks.

FEATURES

- › Cut resistant: Level C (EN 388:2016)
- › 18 gauge seamless liner offers flexibility, comfort and high fingertip sensitivity
- › Free from glass and steel fibre for reduced irritation
- › Foam nitrile coating gives exceptional grip while allowing warm air and moisture from inside to escape, keeping hands dry and comfortable
- › Reinforced thumb crotch enhances durability
- › Designed for easy movement and continuous wear
- › Breathable back of hand to reduce perspiration
- › Seamless knit prevents irritation
- › Elasticated wrist provides a secure fit



SUITABLE FOR

Typical Industries

- Automotive
- Construction
- Logistics
- Maintenance
- Manufacturing
- Transport

Suitable Applications

- Assembly
- Handling sharp and greasy parts
- Machining
- Bodywork
- Precision mechanics

CERTIFICATION

CAT II

EN 388:2016



4X42C

See overleaf for explanation



SAPPHIRE AERO

PRODUCT INFORMATION

MATERIALS	LINER:	18 gauge HPPE
	COATING:	Foam nitrile
COLOUR	Grey/Black	
LENGTH (mm)	250 (Size Dependent)	
CUFF STYLE	Elasticated knit wrist	

RECOMMENDATIONS FOR USE

- **USE:** General handling glove with cut protection. Not suitable for thermal, electrical, chemical protection. Do not use near moving machines if there is a risk of entanglement
- **STORAGE:** Store in dry conditions in the original packaging and away from direct sunlight
- **CLEANING:** To clean, wipe with a damp cloth. Note: The performance characteristics of worn and laundered gloves may differ from the results shown. Inspect the gloves to ensure no damage is present
- **LIFETIME:** Service life depends on the glove application and therefore cannot be specified. It is the responsibility of user to ensure the glove is suitable for its intended use


ORDERING DETAILS

SIZE	CODE	PACKAGING
7/S	SKG00011FD	10 pairs
8/M	SKG00011FF	per bag
9/L	SKG00011FH	
10/XL	SKG00011FJ	120 pairs
11/XXL	SKG00011FL	per case

CERTIFICATION LEGENDS



MECHANICAL HAZARDS EN 388:2016
PERFORMANCE LEVELS*

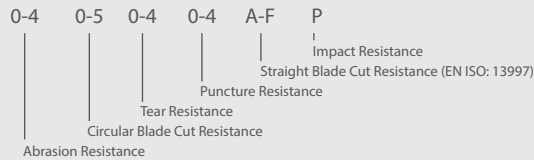

*If tests are not performed or are not applicable, 'X' will be placed instead of a number/letter

EUROPE

www.globusgroup.com

E: sales@globus.co.uk
T: +44 (0)161 877 4747
F: +44 (0)161 877 4746

MIDDLE EAST AND AFRICA

www.globusgroup.com/gcc

E: gcc@globusgroup.com
T: +971 4 882 9962
F: +971 4 882 9963



Globus Group, T2 Trafford Point, Twining Road, Trafford Park, Manchester, M17 1SH, UNITED KINGDOM
 Globus EMEA FZE, Jafza One, Tower A, Office 2201, Jebel Ali, PO Box 61195, Dubai, UNITED ARAB EMIRATES

© 2021 Globus (Shetland) Ltd | SKY-DATA-SAPP-AERO-0921_2