

Datasheet

RS PRO NYLON-FULLY INSULATED TWIN WIRE FEMALE DISCONNECTORS (TA TYPE)

Stock number: 178-8308

MAXIMUM ELECTRIC CURRENT:

A.W.G.	16	14
AMP.	10	15


MAXIMUM ELECTRICAL RATING: 105° C 600 VOLTS MAX.


INSULATION MATERIAL: NYLON

TERMINAL MATERIAL: BRASS

INSULATION COLOR: BLUE

TERMINAL BARREL I.D.: C=2.3MM

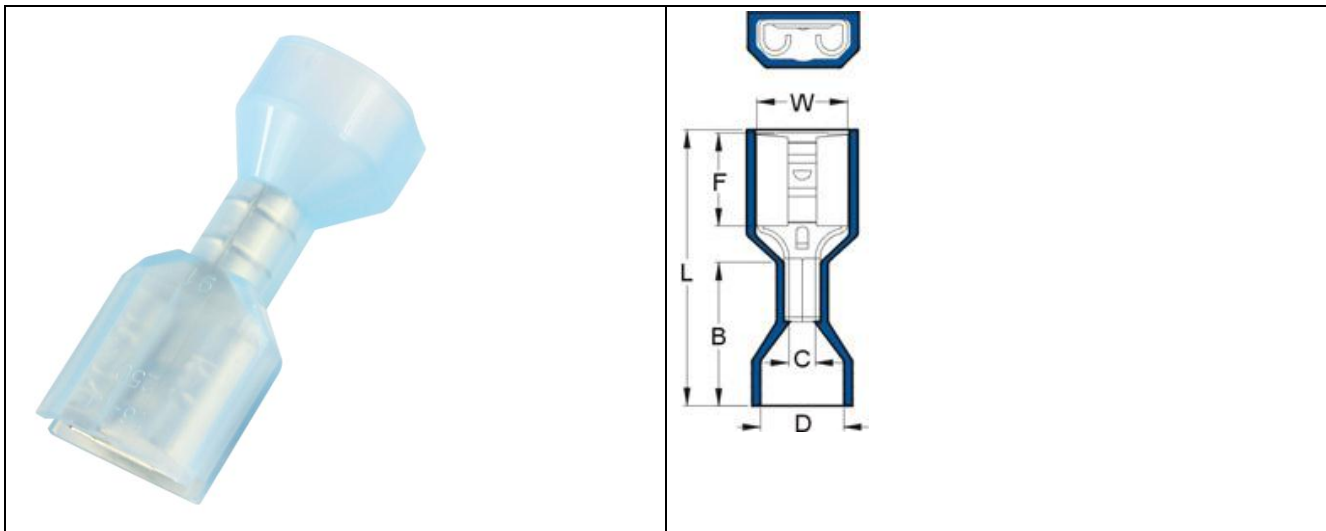

WIRE RANGE A.W.G. mm ²	ITEM NO.	NEMA TAB	DIMENSION inch(mm)					
			W	F	L	B	D	T
16-14 A.W.G. 1.5-2.5 mm ²	 178-8308	.032X.250 (0.8X6.35)	0.264 6.7	0.299 7.6	0.906 23	0.472 12	0.268 6.800	0.016 0.4