


## Technical data


GS81112

Thrust washer

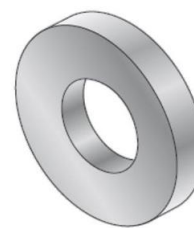

Needle roller bearing, thrust needle roller bearing, outer ring

### VISUAL (S)

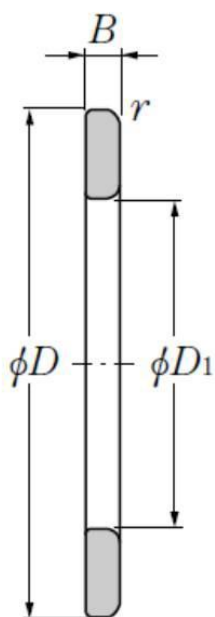

### PRODUCT DEFINITION

|                                                |          |
|------------------------------------------------|----------|
| Brand                                          | NTN      |
| D - Outside diameter of support washer OR - GS | 85 mm    |
| D1 - Bore diameter bearing washer OR - GS      | 62 mm    |
| B - Ring thickness                             | 4,75 mm  |
| rs - Min fillet radius                         | 1 mm     |
| Bearing ring (outer ring) GS mass              | 0,101 kg |

### PRODUCT PERFORMANCE

|                                  |           |
|----------------------------------|-----------|
| Tmin - Min operating temperature | 253,15 °K |
|----------------------------------|-----------|



**NTN Europe**

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00  
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072  
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT PERFORMANCE

|                                  |           |
|----------------------------------|-----------|
| Tmax - Max operating temperature | 393,15 °K |
|----------------------------------|-----------|

