



Spacer plate - DP-PTTBV 2,5/4 - 1088118

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

Spacer plate, length: 99.5 mm, width: 2.6 mm, height: 29.1 mm, color: gray

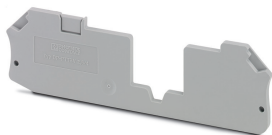

Key Commercial Data

Packing unit	50 pc
Minimum order quantity	50 pc
GTIN	 4 055626 885698
GTIN	4055626885698
Weight per Piece (excluding packing)	3.178 g
Custom tariff number	85389099
Country of origin	India
Sales Key	BE2Z1X

Technical data

General

Color	gray
-------	------

Dimensions

Width	2.6 mm
Length	99.5 mm
Height	29.1 mm

General

Ambient temperature (operation)	-60 °C ... 105 °C (max. short-term operating temperature 130°C)
Ambient temperature (storage/transport)	-25 °C ... 60 °C (for a short time, not exceeding 24 h, -60 °C to +70 °C)
Permissible humidity (storage/transport)	30 % ... 70 %
Ambient temperature (assembly)	-5 °C ... 70 °C
Ambient temperature (actuation)	-5 °C ... 70 °C

Spacer plate - DP-PTTBV 2,5/4 - 1088118

Classifications

eCl@ss

eCl@ss 10.0.1	27141133
eCl@ss 11.0	27141133
eCl@ss 8.0	27141133
eCl@ss 9.0	27141133

ETIM

ETIM 5.0	EC000886
----------	----------