


PHE F110RSBFLG

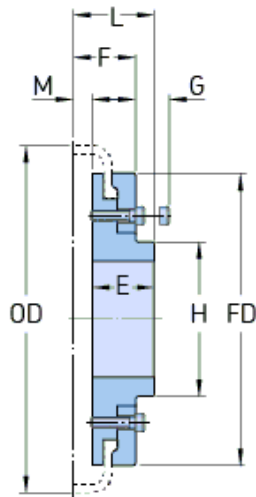

Size	110
Min. bore (mm)	30
Min. bore (in)	1.18
Max. bore (mm)	90
Max. bore (in)	3.54
Weight (kg)	12.5
Weight (lbs)	27.56
E (mm)	63
E (in)	2.48