


# Datasheet

## Connector Assembly

RS Stock 877-1208



### Dimensions: (mm)

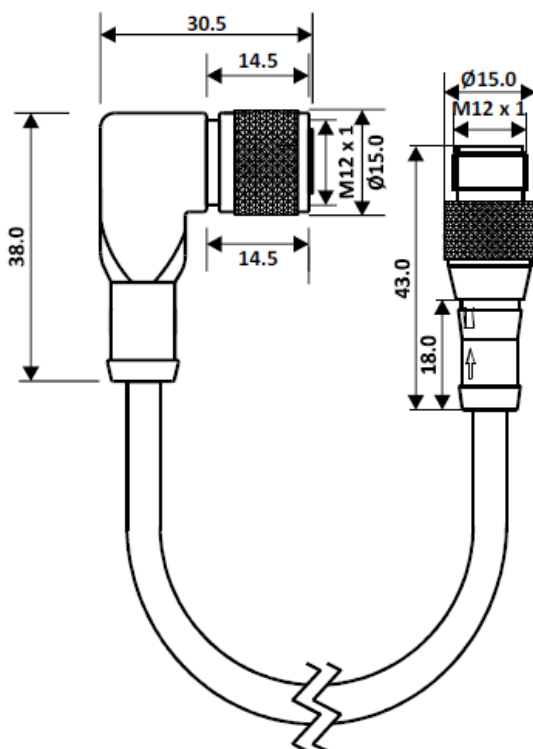

## Specifications

### General Specification

Rated Operational Voltage	30 V
Current Rating	2A
Insulation Resistance	$\geq 100 \text{ M}\Omega$
Temperature Range	-25°C ... +75°C
Degree of Protection	IP67

### Material Specification

Grip Material	PU
Contact	Cu-Zn
Contact Plating	Gold Plated
Contact Carrier	Nylon 66
O-Ring	Neoprene
Grip Colour	Black
Coupling Nut	Brass Nickel-Plated

### Cable Specification

Cable Length-L	2 m
Cable Type	8 Core PVC Multi Strand
Sheath Colour	Black
Cross Section of Wire	0.25 sq. mm
Core Dia	1.25 mm
Cable Dia	$6.4 \pm 0.1 \text{ mm}$
Termination	Partially Stripped