




ENGLISH

Datasheet

Black Fluorocarbon Rubber Sheet, 600mm x 600mm x 1.5mm

RS Stock number [506-2974](#)

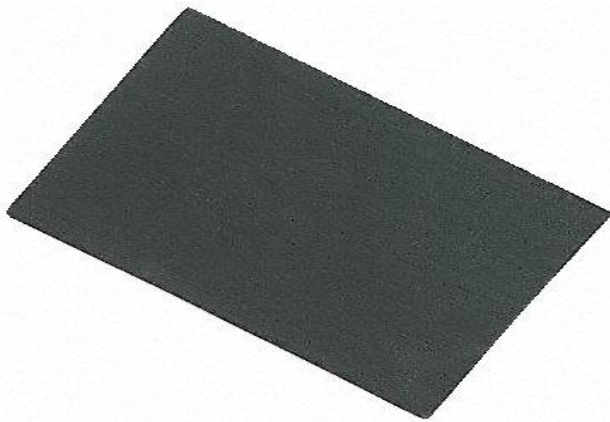

Description:

Fluorocarbon Rubber sheet with good resistance to mineral oils, fuels, non-polar solvents including high aromatic and chlorinated types.

Specifications:

Colour:	Black
Hardness:	70° (+/-5°) Durometer
Tensile Strength:	100 Kg/cm ²
Elongation @ Break:	165% Min
Compression Set:	50% Maximum Discs 22 hours @ 175°C ASTM 395D Plied
Temperature Range:	-18°C to +204°C (up to 315°C intermittent)