


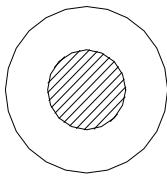

Product Name:	UL1429 24AWG
Product Discription:	UL1429 24AWG
Specification No.:	
Customer's Name:	

Description					Construction							
Rated Voltage:		150V			Conductor		Stranded Tinned Copper					
Rated Temperature:		80℃			Size(AWG)		24					
Reference Standard:		UL758,UL1581			Construction(±0.008mm)		7/0.20					
Cross Section					Stranded Dia.(mm)Ref.		0.6					
					Insulation Material		XLPVC					
					Insulation Color		ANY COLOR					
					Ave Thickness(mm)		0.26					
					Insulation Dia.(±0.06mm)		1.12					
Marking					Remark:							
E148000  AWM STYLE 1429 24AWG 80℃ 150V VW-1 --- C  AWM I A 80℃ 150V FT1 -F- - LF- PC10 LTK					8775323 Red		8775327 Blue		8775345 Grey		8775349 Violet	
					8775311 Black		8775336 White		8775333 Yellow			
					8775320 Brown		8775339 Green		8775342 Orange			
Applications					Characteristics					Customer Approve		
For Internal Wiring of Appliances or Electronic Equipment					Test Item			Standard Value				
					Test Material			XLPVC(ROHS)				
					Max.DC Resistance(20℃ Ω/km)			94.2(MAX)				
					Vol. Tesr(AC.V.60S) (V)			1500				
					Flammability Test			VW-1				
Revisions											Signature: Date:	
Version	Description	Drawn by	Approved by	Date								
0	New document issue	Lisa	Jason	18/05/2015								