


HOSE TAILS

Parallel male thread - Hose tail - 2
barbs - JFT ZS

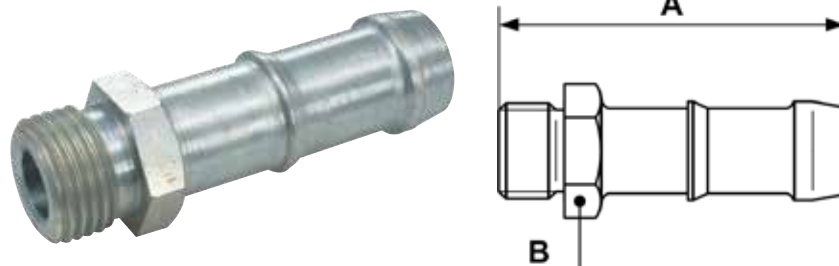

Min / Max operating pressure

0 / 15 bar

Part number	Male thread	Dim. A (mm)	Dim. B (mm)
JFT 1219ZS	G1/2	74	23
JFT 3419ZS	G3/4	78	29
JFT 3425ZS	G3/4	80	35
JFT 0119ZS	G1	84	35
JFT 0125ZS	G1	84	35