


## R.LAT – ¼" 6 Point Long Metric Sockets

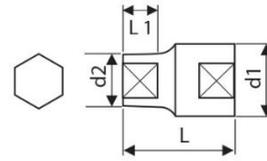

### Description:

- **6-Point OGV® Profile** – Maximising the contact surface with the nut and minimising damage to the fastener
- **NECK-DOWN DESIGN** - Facilitating the use in narrow spaces
- **Matte finish**
- **ACCESSIBILITY** - Long shape which offers better accessibility in deep spaces
- **DIN 3124, ISO 1711-1, ISO 2725-1, NF ISO 1711-1, NF ISO 2725-1**

	Fastener Head Size (mm)	Square Drive	Length L1 (mm)	Diameter D2 (mm)	Weight (g)
R.5LAT	5	¼"	50.5	12	18
R.5.5LAT	5.5	¼"	50.5	12	18
R.6LAT	6	¼"	50.5	12	18
R.7LAT	7	¼"	50.5	12	27
R.8LAT	8	¼"	50.5	12	27
R.9LAT	9	¼"	50.5	12.8	32
R.10LAT	10	¼"	50.5	14.3	41
R.11LAT	11	¼"	50.5	16	54
R.12LAT	12	¼"	50.5	16.8	54
R.13LAT	13	¼"	50.5	18.2	59
R.14LAT	14	¼"	50.5	19.2	68