

# ARCA 404021T No MP



Sample image

**Order symbol :** ARCA 404021T No MP

**Product nr :** 8121009N

**Description :** Cabinet, PC



**Remarks :** Transparent cover, 2-point locking, without mountingplate

**EAN :** 6418074317964

**El. number :**

- Finland : 3425131
- Denmark : 8212056349
- Sweden : 2507051

**Including :** Cabinet base, door with PUR gasket. 3mm double bit lock(s) with key. S versions with swinghandle 2-point locking system. Door guide included.

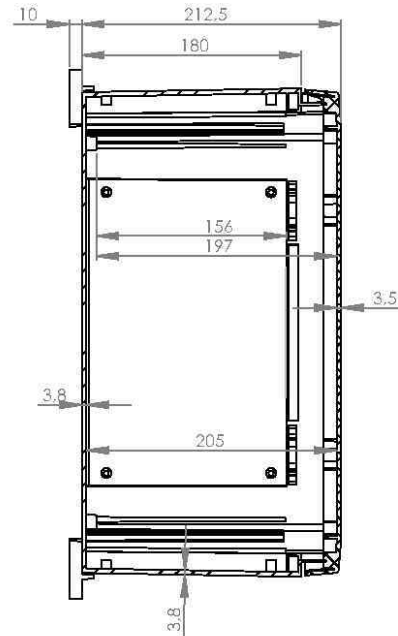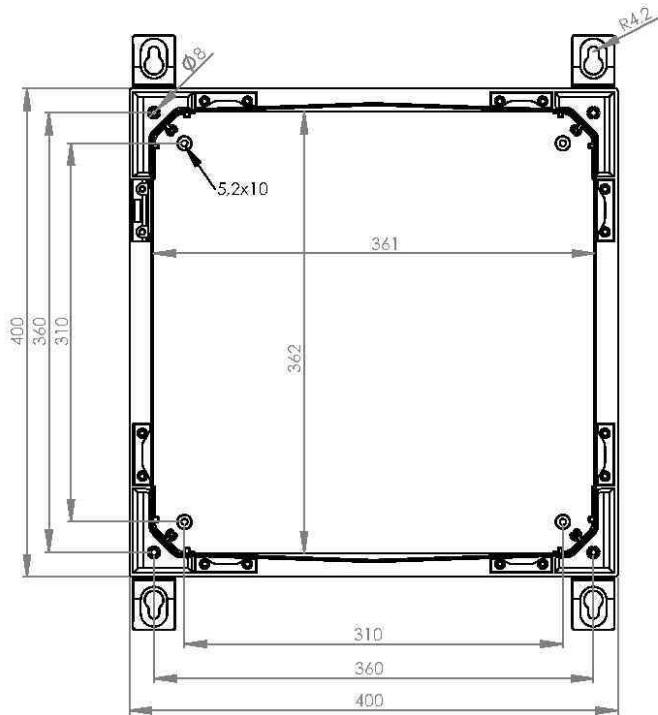

| Dimensions : | Height | Width | Depth |
|--------------|--------|-------|-------|
| mm :         | 400    | 400   | 210   |
| inch :       | 15.75  | 15.75 | 8.27  |

#### Materials :

|                   |               |
|-------------------|---------------|
| Material :        | Polycarbonate |
| Base colour :     | RAL_7035      |
| Cover colour :    | Smoked grey   |
| Gasket material : | Polyurethane  |

#### Temperatures :

|                               |             |
|-------------------------------|-------------|
| Temperature °C (continuous) : | -40 ... 80  |
| Temperature °F (continuous) : | -40 ... 175 |

#### Accessories :

|                 |                                                                              |
|-----------------|------------------------------------------------------------------------------|
| PMK ARCA 40     | PoleMounting kit, for pole ø100-300mm<br>(385 x 285 x 35)                    |
| IDS ARCA 4040   | Inner door set<br>(380 x 380 x 30)                                           |
| MPX ARCA 4040   | Mounting plate (350x350 mm)<br>(350 x 350 x 5)                               |
| MPMP ARCA 4040  | Mounting plate multiperforated (350x350x2 mm - ø3.6 mm)<br>(350 x 350 x 1.5) |
| DRS ARCA 404021 | DIN rail frame set<br>(380 x 380 x 30)                                       |
| MPS ARCA 4040   | Mounting plate (350x250x2 mm)<br>(350 x 350 x 2)                             |
| MPP ARCA 4040   | Mounting plate perforated (350x350x2 mm - 26x11 mm)<br>(350 x 350 x 2)       |

#### Ratings :

|                                         |                   |
|-----------------------------------------|-------------------|
| Ingress protection (EN 60529):          | IP66;             |
| Impact Resistance (EN 62262):           | IK09;             |
| electrical_insulation :                 | Totally insulated |
| Halogen free (DIN/VDE 0472, Part 815) : | Yes               |

|                                   |                  |
|-----------------------------------|------------------|
| UV resistance :                   | UL 746C          |
| Flammability Rating :             | UL 94 5VA        |
| Glow Wire Test (IEC 695-2-1) °C : | 960C             |
| UL Type                           | 1, 4, 4X, 12, 13 |

**Certificates :**

Certificate FI 40467