


Masking frame 3VA20 (100 A), 3VA21 (160 A), 3VA22 (250 A), 3 or 4-pole, fixed-mounted, drive: direct, front-mounted rotary operator, motorized operating mechanism, RCD: with, H: 200 mm W: 600 mm

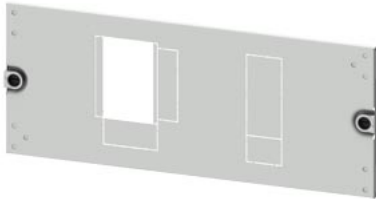

Model	
product brand name	SIVACON S4
design of the surface	powder-coated
net weight	0.97 kg
height	200 mm
width	600 mm
depth	10 mm
installation width for cabinet installation	600 mm
mounting height for device equipment can be used	200 mm
material	sheet-steel
reference code according to IEC 81346-2	UC

Approvals Certificates	
General Product Approval	other



[Miscellaneous](#)



[Confirmation](#)

Environment

[Environmental Con-
firmations](#)

[Environmental Con-
firmations](#)

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8PQ2020-6BA40>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8PQ2020-6BA40>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)

http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8PQ2020-6BA40

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

