


Sub-base VABS-K2-10S-16-M6-P

Part number: 8122827

FESTO

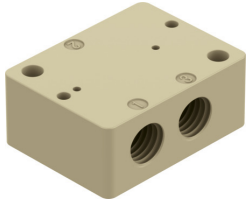

 [General operating condition](#)

Data sheet

Feature	Value
Size	10
Nominal size	1.6 mm
Fluid connection	M6 female thread
Mounting position	optional
Design	Connection direction at side
Max. number of valve positions	1
Flow direction	Non-reversible
Operating medium	Liquid media Gaseous media
Note on operating and pilot medium	Observe resistance of materials that come into contact with the media
Corrosion resistance class CRC	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-20 °C ... 70 °C
Media temperature	0 °C ... 50 °C
Ambient temperature	0 °C ... 50 °C
Max. tightening torque for valve mounting	0.2 Nm
Max. tightening torque	0.6 Nm
Product weight	7 g
Mounting method for sub-base	With through-hole
Mounting method for valve	Via female thread
Note on materials	RoHS-compliant
Material sub-base	PEEK