


Epoxy base without resin, 8/10th - 18 microns of copper - 2 sides - CIF

Product Epoxy base without resin, 8/10th - 18 microns of copper - 2 sides

Reference Size in mm - 200 x 300 : AEG20
Size in mm - 148 x 210 : AEG14



Product Image

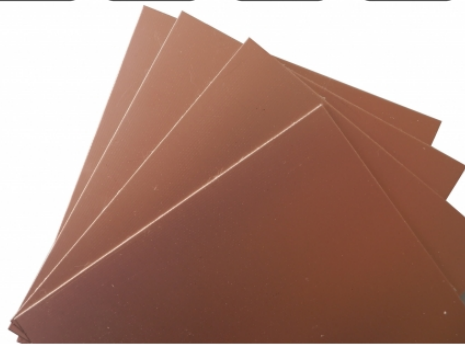

Summary

- High qualified stratified.
 - 8 layers of glass cloth
 - MIL 13949 F standard
 - Flammability class UL94V0
 - Moisture absorption
-