



NT 70/3

Powerful wet and dry vacuum cleaner with 70 l container capacity and up to three motors.

1 Integrated accessory storage

- Large bumper with accessory storage.

2 Integrated drain hose

- The container is easy to empty via the drain hose. Extremely practical due to the very large 70 litre container capacity.

3 Ergonomic push handle

- The NT 70 has an ergonomic push handle so that the machine can be pushed along.

4 Robust bumper

- The robust bumper protects the machine from knocks and bumps.



NT 70/3

- Robust bumper, large wheels
- Ergonomic push handle
- Optional wet filter available

Technical data

Order no.	1.667-270.0	
EAN code	4039784725386	
Supply voltage	Ph / V / Hz	1 / 220 - 240 / 50 - 60
Air flow	l/s	3 x 74
Vacuum	mbar / kPa	254 / 25.4
Container content	l	70
Container material	Plastic	
Rated input power	W	3600
Standard nominal width	DN 40	
Cable length	m	10
Sound pressure level	dB(A)	79
Weight	kg	27.6
Dimensions (L x W x H)	mm	720 x 510 x 975

Equipment

Suction hose	m	4 / with bend
Suction tube	piece(s) x m	2 x 0.5 / Metal
Wet/dry floor nozzle	mm	400
Crevice nozzle	■	
Drain hose	■	
Cartridge filter	Paper	
Sturdy bumper	■	
Push handle	■	
Protection class	II	

■ Included in the scope of supply.


NT 70/3

1.667-270.0



		Order no.	Quantity				Price	Description	
Cartridge filter paper									
Cartridge filter, paper	1	6.907-038.0	1 piece(s)					Paper cartridge filter (M BIA-C dust class M), suitable as a main filter for dry and wet pick up.	■
Coarse dirt filter for wet vacuuming									
Foam filter	2	2.889-083.0	1 piece(s)					Not suitable for dry vacuuming.	□
Wet filter bag									
Wet filter bag	3	6.904-252.0	5 piece(s)					Approved for dust class L, general cleaning, wet and dry, tear-resistant.	□
Paper filter bags									
Paper filter bags	4	6.904-285.0	5 piece(s)					5 3-ply, tear-resistant paper filter bags. BIA-(U, S, G, C) dust class M. For all NT 48/1, NT 65/2 Eco + Me and NT 72/2 Eco Tc models.	□
Plastic sacks for dust-free disposal									
Plastic bag for dust-free disposal	5	6.900-698.0	10 piece(s)					PE plastic sack.	□
Fabric filter									
Membrane filter	6	6.904-282.0	1 piece(s)					Polyester needle fleece membrane/fabric filter - BIA-C -, washable up to 40°C, metal fibres for earthing. Suitable for virtually all industrial two-motor NT vacuum cleaners.	□
Fleece filter bags									
Fleece filter bags	7	2.885-753.0	5 piece(s)					Large, tear-resistant, triple-layer fleece filter bags for all twin-motor wet and dry vacuum cleaners from Kärcher. Certified according to dust class M, suitable for container sizes from 65 to 75 litres.	□

■ Included in the scope of supply. □ Available accessories.

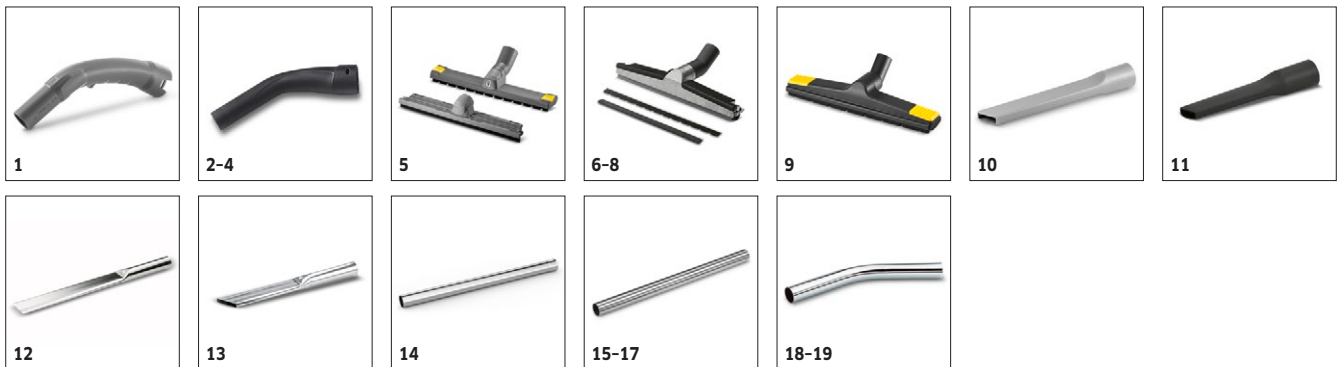

		Order no.	Quantity	ID	Length	Width	Price	Description	
Bend, plastic									
DN 40 bend	1	2.889-171.0	1 piece(s)	DN 40				Bend for the new clip system in nominal size DN 40.	■
Plastic bend	2	5.031-718.0	1 piece(s)	DN 35				Plastic bend (DN 35) with C-35 clip system. For all industrial single-motor NT 361 to NT 611 Eco models (except NT Eco M and NT Eco H).	□
Bend, plastic, electrically conductive	3	5.031-939.0	1 piece(s)	DN 35				Electrically conductive plastic bend (DN 35) with C-35 clip system. For all industrial single-motor NT 361 to NT 611 Eco models.	□
	4	5.032-427.0	1 piece(s)	DN 40				Electrically conductive plastic bend (DN 40) with C-40 clip system, suitable for all NT vacuum cleaners.	□
Floor nozzles									
Wet/dry floor nozzle, plastic Adv, DN 40	5	2.889-153.0	1 piece(s)	40		360 mm		360 mm wide wet and dry floor nozzle with easy-to-change inserts, squeegees.	■
Wet and dry floor nozzle, aluminium, DN 40	6	6.903-018.0	1 piece(s)	40		370 mm		All-purpose aluminium nozzle with 370 mm working width. With height-adjustable side rollers, brush strips (6.903-064.0) and oil-resistant squeegees (6.903-081.0). Only for NT vacuum cleaners.	□
Multi-purpose nozzle, wet/dry	7	6.906-383.0	1 piece(s)	40		450 mm		All-purpose aluminium nozzle (DN 40) with 450 mm working width. With height-adjustable side rollers, brush strips (6.903-065.0) and oil-resistant squeegees (6.906-146.0). Only for NT vacuum cleaners.	□
	8	6.906-384.0	1 piece(s)	35		370 mm		All-purpose aluminium nozzle (DN 35) with 370 mm working width. With height-adjustable side rollers, brush strips (6.903-064.0) and oil-resistant squeegees (6.903-081.0). Only for NT vacuum cleaners.	□
Wet and dry floor nozzle	9	2.889-117.0	1 piece(s)	40		400 mm		The wet and dry floor nozzle (DN 40) allows quick changing of the squeegees/brush and is ideal for wet vacuum cleaning of large areas.	□
Crevice nozzles									
DN 40 crevice nozzle for wet and dry vacuum cleaner	10	5.130-655.0	1 piece(s)	DN 40				Plastic crevice nozzle in nominal width DN 40 for Kärcher wet and dry vacuum cleaners. Especially suitable for vacuuming out areas that are difficult to reach, such as joints, crevices and corners.	■
Crevice nozzle	11	6.900-385.0	1 piece(s)	DN 35	210 mm			Plastic crevice tool (DN 35) for vacuuming in crevices and corners. Length: 210 mm.	□
	12	6.900-922.0	1 piece(s)	35 mm	500 mm			Plastic crevice tool (DN 35) for vacuuming in crevices and corners. Length: 370 mm.	□
	13	6.905-817.0	1 piece(s)	40 mm	400 mm			Metal crevice tool (DN 40) for vacuuming in crevices and corners. Length: 400 mm.	□
Suction tubes, stainless steel									
Set suction tube stainless steel NW40 55	14	2.889-194.0	2 piece(s)	40	550 mm			Stainless steel suction tube set (2 × 0.55 m)	■
Suction tube	15	6.902-081.0	1 piece(s)	40	500 mm			Stainless steel suction tube (DN 40, 0.5 m) only suitable for NT vacuum cleaners.	□
	16	6.906-531.0	1 piece(s)	40	1000 mm			Stainless steel suction tube (DN 40, 1.0 m) only suitable for NT vacuum cleaners.	□
	17	6.902-154.0	1 piece(s)	35	500 mm			0.5 m long stainless steel suction tube (ID 35) for wet and dry vacuum cleaners. Ideal for frequent wet vacuuming applications and for vacuuming corrosive components.	□
Bends, stainless steel									
Bend, stainless steel, ID 35	18	6.903-141.0	1 piece(s)	DN 35				Stainless steel and crooked, ID 35	□
Bend, stainless steel, ID 40	19	6.902-079.0	1 piece(s)	DN 40				Stainless steel and crooked, ID 40	□

■ Included in the scope of supply. □ Available accessories.

NT 70/3

1.667-270.0

KÄRCHER



		Order no.	Quantity	ID	Length	Width	Price	Description	
Bends, metal									
Bend, metal	20	6.900-519.0	1 piece(s)	DN 35				Robust, chromium-plated metal bend (DN 35), can be used instead of a plastic bend (with clip system adapter 5.407-112.0, C 35-DN 35, plastic, el).	<input type="checkbox"/>
	21	6.900-276.0	1 piece(s)	DN 40				Robust, chromium-plated metal bend (DN 40), can be used instead of a plastic bend (with clip system adapter 5.407-111.0, C 40-DN 40, plastic, el).	<input type="checkbox"/>
All-purpose brushes									
All-purpose brush	22	6.903-863.0	1 piece(s)	35 mm	120 mm			Natural bristles (ox hair), bristle element 120 x 45 mm.	<input type="checkbox"/>
Car cleaning nozzles									
DN 40 car nozzle	23	6.900-952.0	1 piece(s)	DN 40		90 mm		For retrofitting older Kärcher wet and dry vacuum cleaner models with bends in DN 40: Flat angled, convenient, plastic car cleaning nozzle with a working width of approx. 90 mm.	<input type="checkbox"/>
Wide nozzles									
Wide nozzle	24	4.130-432.0	1 piece(s)	40 mm		644 mm		Vacuuming larger Areas in connection with NT 70/1, NT 70/2 or NT 70/3 versions only.	<input type="checkbox"/>
Rubber suction tools, nose 45°									
Rubber suction tool, nose 45°	25	6.902-104.0	1 piece(s)	35 mm	220 mm			45° rubber suction nozzle (DN 35), oil-resistant and suitable for vacuuming machines. Only for NT vacuum cleaners.	<input type="checkbox"/>
	26	6.902-105.0	1 piece(s)	40 mm	220 mm			45° rubber suction nozzle (DN 40), oil-resistant and suitable for vacuuming machines. Only for NT vacuum cleaners.	<input type="checkbox"/>
Pipe dusting nozzles									
Pipe brush 35/100	27	6.903-035.0	1 piece(s)	35 mm				Plastic, pipe diameter 100 mm	<input type="checkbox"/>
Pipe brush 35/200	28	6.903-036.0	1 piece(s)	35 mm				Plastic, pipe diameter 200 mm	<input type="checkbox"/>
Suction brushes									
Suction brush	29	6.903-862.0	1 piece(s)	35 mm		70 mm		Rotatable suction brush (DN 35) with high-quality synthetic hair bristles. Dimensions of the brush attachment: 70 x 45 mm.	<input type="checkbox"/>
	30	6.903-887.0	1 piece(s)	32 mm		70 mm		Rotatable suction brush (DN 32 plastic) with PA bristles, 70x45 mm. Only for BV and T vacuum cleaners.	<input type="checkbox"/>
Suction tubes, metal									
Suction tube	31	6.900-514.0	1 piece(s)	35	500 mm			Chromium-plated metal suction tube (DN 35, 1x0.5 m), standard for virtually all single-motor industrial NT vacuum cleaners.	<input type="checkbox"/>

■ Included in the scope of supply. □ Available accessories.




		Order no.	Quantity	ID	Length		Price	Description	
Complete suction hoses (clip system)									
Suction hose DN 40, length 4 m	1	2.889-138.0	1 piece(s)	DN 40	4 m			4 m long suction hose with new bayonet and clip fastener.	<input checked="" type="checkbox"/>
Suction hose + ID 40 bushing	2	4.440-784.0	1 piece(s)	DN 40	16 m			C ID 40, 16 m, with bayonet connection and straight sleeve.	<input type="checkbox"/>
Electrically conductive suction hose	3	2.889-137.0	1 piece(s)	DN 35	4 m			4 m suction hose with new bayonet and clip fastener. Electrically conductive.	<input type="checkbox"/>
Suction hose	4	2.889-139.0	1 piece(s)	DN 40	2.5 m			Suction hose with new bayonet and clip fastener. Length: 2.5 m.	<input type="checkbox"/>
Suction hose, oil-resistant	5	2.889-140.0	1 piece(s)	DN 40	4 m			Oil-resistant suction hose with new bayonet and clip fastener. Length: 4 m.	<input type="checkbox"/>
Electrically conductive suction hose	6	2.889-141.0	1 piece(s)	DN 40	4 m			4 m long, electrically conductive suction hose with new bayonet and clip fastener.	<input type="checkbox"/>
	7	2.889-142.0	1 piece(s)	DN 40	2.5 m			Suction hose, electrically conductive, with new bayonet and clip fastener. 2.5 m long.	<input type="checkbox"/>
Repair kits									
Repair kit, C 40	8	2.639-873.0	1 piece(s)	C- 40				Suction hose repair kit (clip system).	<input type="checkbox"/>
Repair kit, ID 61	9	2.862-038.0	1 piece(s)	DN 61				Suction hose repair kit.	<input type="checkbox"/>
Repair kit ID 40	10	2.889-150.0	1 piece(s)	DN 40				Repair kit ID 40 for the new clip system.	<input type="checkbox"/>
Suction hoses (clip system)									
Suction hose	11	6.906-279.0	1 piece(s)	DN 40	10 m			With bayonet and clip connection, C-45.	<input type="checkbox"/>
	12	6.906-321.0	1 piece(s)	40	4 m			With bayonet and clip connection, C 40.	<input type="checkbox"/>
	13	6.906-635.0	1 piece(s)	DN 40	16 m			With bayonet and clip connection, C-40.	<input type="checkbox"/>
	14	6.906-877.0	1 piece(s)	DN 40	10 m			With bayonet and clip connection, electrically conductive, C-40.	<input type="checkbox"/>
Suction hoses complete									
Suction hose, complete	15	4.440-264.0	1 piece(s)	DN 61	4 m			Plastic.	<input type="checkbox"/>
	16	4.440-328.0	1 piece(s)	DN 61	3 m			Industrial hose, PVC / elastomer with steel spiral, smooth inside.	<input type="checkbox"/>
	17	4.440-467.0	1 piece(s)	DN 61	10 m			Plastic.	<input type="checkbox"/>
Suction hose, complete, oil-resistant	18	4.440-613.0	1 piece(s)	DN 61	4 m			Oil-resistant.	<input type="checkbox"/>
Suction hose, complete, electrically conductive	19	4.440-616.0	1 piece(s)	DN 61	4 m			Electrically conductive.	<input type="checkbox"/>
Suction hose, complete	20	4.440-263.0	1 piece(s)	DN 40	4 m			Plastic.	<input type="checkbox"/>
	21	4.440-303.0	1 piece(s)	DN 40	4 m			Oil-resistant.	<input type="checkbox"/>
	22	4.440-463.0	1 piece(s)	DN 40	10 m			Plastic.	<input type="checkbox"/>
	23	4.440-466.0	1 piece(s)	DN 40	10 m			Electrically conductive, plastic.	<input type="checkbox"/>
Suction hose, complete, oil-resistant	24	4.440-612.0	1 piece(s)	DN 40	10 m			Oil-resistant.	<input type="checkbox"/>
Hose connection									
Adapter, ID 32/35, with internal thread	25	6.902-077.0	1 piece(s)	DN 32				For connecting two suction hoses (not ESB 28 and 34).	<input type="checkbox"/>
Connecting adapter, ID 40, with internal thread	26	6.900-286.0	1 piece(s)	DN 40				For connecting two suction hoses, threaded at both ends.	<input type="checkbox"/>
Extension hoses (clip system)									
Extension hose	27	6.906-344.0	1 piece(s)	DN 40	2.5 m			For all C-40 hoses.	<input type="checkbox"/>
	28	2.889-146.0	1 piece(s)	DN 40	2.5 m			Extension hose for new clip system ID 40. Length: 2.5 m.	<input type="checkbox"/>

■ Included in the scope of supply. □ Available accessories.

NT 70/3

1.667-270.0

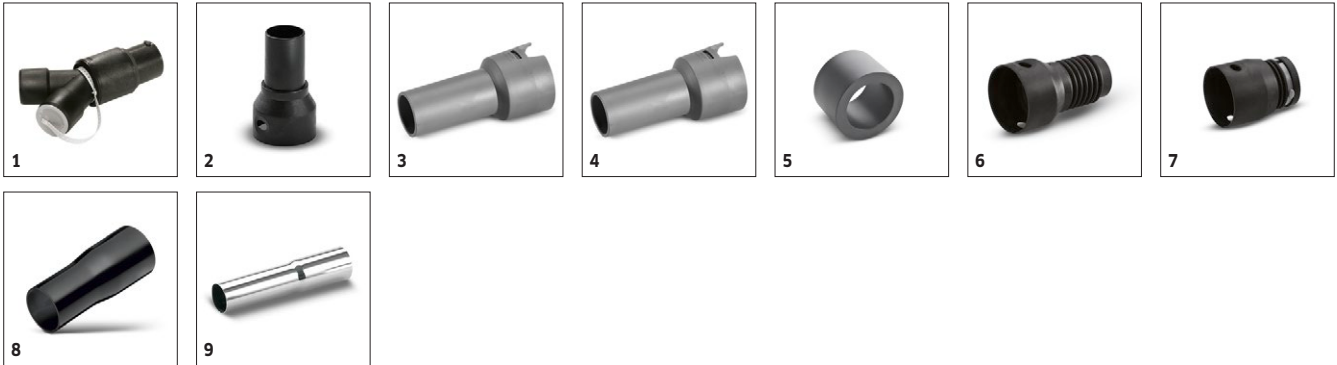

		Order no.	Quantity	ID		Price	Description	
Y-adapter kit								
Y-adapter kit	1	2.637-217.0	1 piece(s)	35 mm			Plastic distributor - suitable for NT vacuum cleaners.	<input type="checkbox"/>
Connection adapter C ID (clip to cone), electrically conductive								
Connection adapter C DN 35	2	5.407-112.0	1 piece(s)	35 mm			C 35 hose connector for DN 35 accessory, electrically conductive.	<input type="checkbox"/>
Adapter clip DN 35 on cone DN 35	3	5.407-005.0					Adapter clip system DN 35 for connecting suction tubes and small nozzles to cone DN 35. Perfect for vehicle interior cleaning, even without the connection of other nozzles.	<input type="checkbox"/>
Adapter clip DN 40 to cone DN 40	4	5.407-006.0		DN 40			For connecting small nozzles and suction tubes with cone DN 40. Adapter clip system DN 40. Ideal for vehicle interior cleaning tasks, with no need to connect additional nozzles.	<input type="checkbox"/>
Expansion pieces (tube -> nozzle)								
Adapter	5	5.453-019.0	1 piece(s)	40 mm			From DN 40 to DN 61: Plastic adapter (electrically non-conductive). Suitable for NT vacuum cleaners.	<input type="checkbox"/>
Reducing sleeves								
Reducer	6	5.407-108.0	1 piece(s)	40 mm			Threaded reducer - from C-40 to DN 35. Suitable for NT vacuum cleaners.	<input type="checkbox"/>
NT reduction bushing with clip system for DN 40 suction hoses on accessory DN 35	7	5.407-113.0	1 piece(s)	40 mm			Reducer (C 40 to C 35) for connecting accessories with C-35 clip connection to suction hoses with C 40 clip system.	<input type="checkbox"/>
Reducers (tube -> nozzle)								
Reducer	8	6.902-017.0	1 piece(s)	40 mm			Reducer for accessory extension. Ideal for accessories with DN 35 connecting cone in combination with accessories with DN 40 connecting cone.	<input type="checkbox"/>
Reducer from ID 35 to ID 32	9	6.902-072.0	1 piece(s)	35 mm			Reducer with internal connecting cone DN 32. Ideal for accessories from the industrial vacuum cleaner range in combination with industrial NT vacuum cleaners.	<input type="checkbox"/>

■ Included in the scope of supply. □ Available accessories.

NT 70/3

1.667-270.0



		Order no.	ID					Price	Description	
Target-group-specific accessory kits for vacuum cleaners										
Professional cleaning kit NT DN 40	1	2.637-353.0	DN 40						Professional wet and dry accessory kit in nominal size DN 40 for Kärcher vacuum cleaners. The wet and dry professional cleaning kit comprises a suction hose, bend, two suction tubes, crevice nozzle and floor nozzle.	<input type="checkbox"/>
Car cleaning accessory kit	2	2.862-166.0	DN 35						Vehicle interior cleaning accessory kit in nominal width DN 35 for Kärcher wet and dry vacuum cleaners. The kit comprises various nozzles and adapter pieces in nominal widths DN 35 and DN 40.	<input type="checkbox"/>
Swarf kit	3	2.640-760.0	DN 61						Wet and dry accessory kit in nominal size DN 61 for vacuuming chips with Kärcher vacuum cleaners. The chip kit comprises an oil-resistant suction hose, a crevice nozzle and a rubber suction nozzle.	<input type="checkbox"/>

■ Included in the scope of supply. □ Available accessories.

NT 70/3

1.667-270.0



1



2

		Order no.	Quantity	Width			Price	Description	
Other accessories NT									
CS 40 Me	1	2.863-026.0	1 piece(s)					The highly efficient CS 40 Me cyclone preseparator for all Kärcher wet and dry vacuum cleaners is a specially designed accessory for fine dust applications on construction sites or in industry.	<input type="checkbox"/>
Adapter connection, electroconductive	2	5.031-436.0						Electroconductive, universal adapter for connecting old NT hoses of nominal widths DN 35, 40, 50 to the new accessory system for wet and dry vacuum cleaners from Kärcher.	<input type="checkbox"/>

■ Included in the scope of supply. □ Available accessories.

NT 70/3

1.667-270.0



		Order no.	Length	Colour	Quantity	Price	Description	
Miscellaneous								
Extension cable	1	6.647-022.0	20 m		1 piece(s)		Extension cable, 20 m, 3x1.5 mm ² . With splash-proof earthing pin plug, strain relief and anti-kink sleeve.	<input type="checkbox"/>

■ Included in the scope of supply. Available accessories.