

SUNNEX TELLUS R/W

Sunnex Tellus R/W is a LED-task light designed specifically for vehicle and applications where night vision is of great importance. Such applications can be a ship bridge or a train cab.

The lamp head is made from durable aluminium and the sturdy flexible arm allows for accurate adjustment of the lamp head position yet maintaining good vibration resistance.

The light colour can easily be switched between white and red light, the built-in dimming function allows for precise adjustment of the light intensity, down to approximately 2% intensity. Tellus R/W has an extended shade for protection against glare and provides a focused light pattern. Supply voltage is SELV 12-24V for direct connection in vehicles and similar applications, adaptor for connection to the power net is available as an accessory.

Suitable applications are ships, trains and other vehicles.

Our accessories like C-clamp, wall bracket, magnetic base and table base can be used with this product.

Customized versions are available upon request.

Features include

- Flexible arm
- Long technical life > 30.000h
- 12-24V AC/DC supply voltage
- Red and white light colour
- Dimmable

Applications

- Ship bridges
- Train cabs
- Road going vehicles




Benefits

- Low power consumption
- Very low heat emission
- Red and white light colour
- Flexible arm for accurate adjustment





- Supply voltage 12-24 AC/DC 2m cord set (100-240VAC Plugin AC/ DC-Adaptor available, as accessory, IP44)
- Power consumption 5W
- Technical lifespan >30.000h
- Arm length 500/700mm
- Colour Black
- Colour temperature 6500K/ Red – 630nm
- IP-rating IP43, IP20
- Protection Class III
- Beam angle 45°
- Light output 77Lm, White 600 Lx @ 50cm distance, Red 150Lx @ 50cm distance
- Colour rendering index CRI: 80 (6500K)
- EMC EN 55015: 2019 + A11:2020, EN 60533:2015 (Bridge)

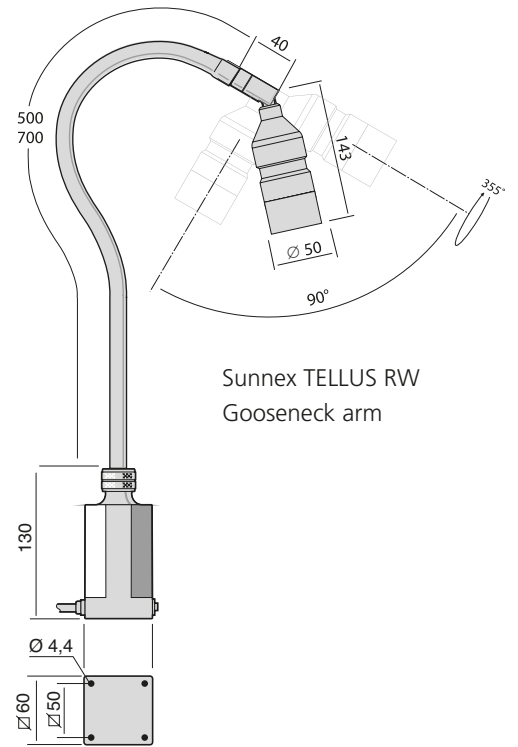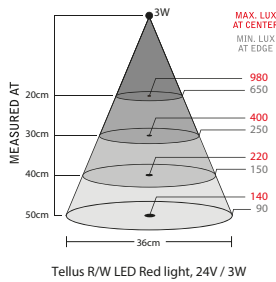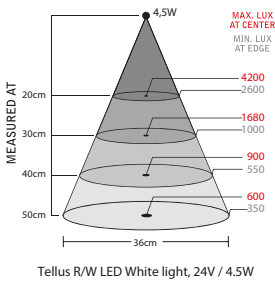

Model	Arm	Connection	Other	Part.no
Tellus RW	500 mm	12-24V AC/DC	IP43	34500
	500 mm		Joint, IP20	34510
	700 mm		IP43	34520
	700 mm		Joint, IP20	34530

PSU accessory



Plug-in Adaptor for Europe 230V
33901

Mounting Accessories



Magnetic base
14000

 


Table base
14015



C-Clamp
14020



Wall mount
14030

More info about
Accessories
see separate leaflet
www.sunnex.se