



by Honeywell

## Technical Specifications

### **PSS WEB MOBILE LIFELINE 20M + 2 SLINGS**

**Reference :** 1031456

#### **Webbing horizontal lifeline**

##### Features

- Webbing temporary horizontal lifeline adjustable from 5 to 20 m
- Supplied in a bag
- Breaking strength : > 20 KN
- Maximum deflexion : 2m
- EN 795 classe b
- Weight : approx. 4,54 Kgs
- Temperature : -30°C to +50°C

- Webbing :

Polyester 35mm webbing

Breaking strength : > 4500 daN


- Webbing Adjuster :

bichromate steel adjuster

Breaking strength : > 1500 daN



DEFLEXION IN CASE OF FALL			
Length of the line	Number of users	Deflexion	Strength at the extremity
5 meters	2	0,50m	1450 daN
10 meters	2	1m	1300 daN
20 meters	2	2m	1200 daN

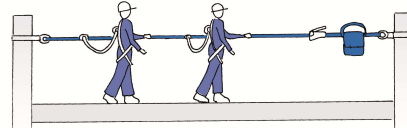

#### **Textile sling**

##### Features :

Orange & black webbing :

Raw material: polyamide webbing

Width: 25 mm

EN 795 / EN 566

#### **Packaging**



HONEYWELL FALL PROTECTION FRANCE SAS

35-37 rue de la Bidauderie

F - 18100 Vierzon - France

Tel : +33 2 48 52 40 40

Fax : +33 2 48 71 04 97

Web site : [www.honeywellsafety.com](http://www.honeywellsafety.com)