

Screw connection - HC-SKV 16 MS - 1676938


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Brass screw connection, Pg16



Key commercial data

Packing unit	10 pc
GTIN	 4 017918 129552
Weight per Piece (excluding packing)	33.1 g
Custom tariff number	85369010
Country of origin	Germany
Note	Made to Order (non-returnable)

Technical data

Dimensions

Wrench size, union nut	8 mm
Wrench size, support	14 mm
External cable diameter	8 mm ... 14 mm

Ambient conditions

Degree of protection	IP65
	IP65
Ambient temperature (operation)	-40 °C ... 125 °C

General

Cable gland material	Nickel-plated brass
Shielded	No
Thread type on connection side	Pg16

Screw connection - HC-SKV 16 MS - 1676938

Classifications

eCl@ss

eCl@ss 4.0	27141209
eCl@ss 4.1	27141209
eCl@ss 5.0	27149109
eCl@ss 5.1	27149109
eCl@ss 6.0	27149109
eCl@ss 7.0	27149109

ETIM

ETIM 2.0	EC000441
ETIM 3.0	EC000441
ETIM 4.0	EC000441
ETIM 5.0	EC000441

UNSPSC

UNSPSC 6.01	30211808
UNSPSC 7.0901	39121408
UNSPSC 11	39121408
UNSPSC 12.01	39121408
UNSPSC 13.2	39121408

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approvals submitted


Approval details

EAC

Drawings

Screw connection - HC-SKV 16 MS - 1676938

Dimensioned drawing

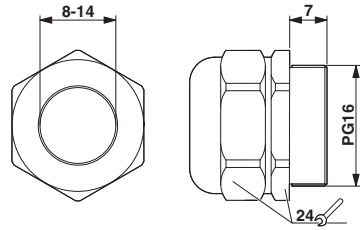

Dimensional drawing

Phoenix Contact 2015 © - all rights reserved
<http://www.phoenixcontact.com>